

# Dynabug® “Model T”

## Air-Powered Orbital Finishing Sander




**SANDING PADS**  
PAGE 237


**COUPLER/PLUG**  
PAGE 222

### Featheredge, Finish, Sand and Blend

- 3/32" diameter orbital action is ideal for fine finishes.
- Lightweight... only 1 lb.! Palm-style, ergonomic design features low profile grip for greater operator comfort and control.
- Operates 9 SCFM at 90 PSIG. Can be run by as little as 3 horsepower compressor.
- Low maintenance – easy to repair. Turbine-style vaneless air motor needs no oil!
- Easily interchangeable sanding pads. Accepts reattachable and PSA (adhesive-backed) abrasive sheets and discs; coated and non-woven nylon.
- Each model includes 95955 Urethane Inlet Hose.

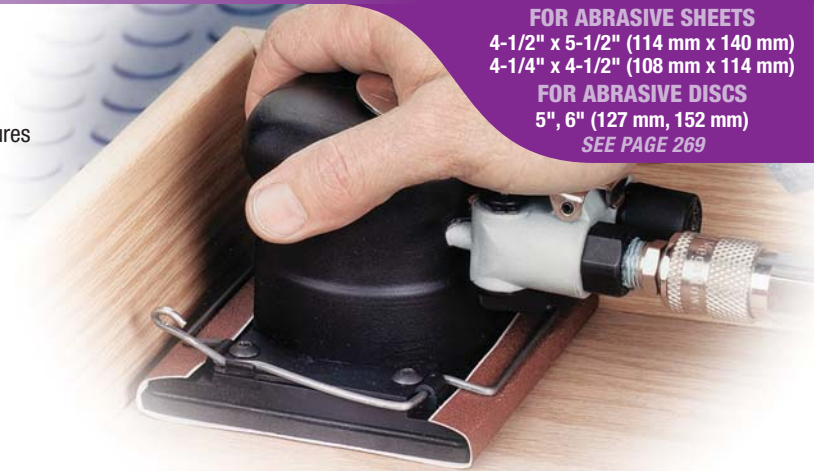

**FOR ABRASIVE SHEETS**  
4-1/2" x 5-1/2" (114 mm x 140 mm)  
4-1/4" x 4-1/2" (108 mm x 114 mm)  
**FOR ABRASIVE DISCS**  
5", 6" (127 mm, 152 mm)  
*SEE PAGE 269*

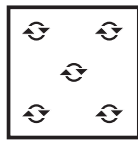

**Orbital Motion**

### Non-Vacuum

#### Model 57920 4" x 4-5/16" Pad (with clips)

- Includes 57999 Vinyl-Face Pad.

#### Model 57923 4-1/4" x 4-1/2" “Quarter-Sheet” Pad

- Includes 57998 Hook-Face Pad.

#### Model 57925 4-1/4" x 4-1/2" “Quarter-Sheet” Pad

- Includes 56244 Vinyl-Face Pad.



Model 57923

*See page 237 for Dynabrade Sanding Pads!*



Equipped with 96455 Urethane Inlet Hose

(All models on page)




Model 57925

#### Model 57922 5" Diameter

- Includes 56249 Vinyl-Face Pad.

#### Model 57924 5" Diameter

- Includes 56248 Hook-Face Pad.

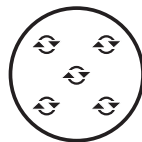

**Orbital Motion**




Model 57926

#### Model 57926 6" Diameter

- Includes 56269 Vinyl-Face Pad.

#### Model 57927 6" Diameter

- Includes 56268 Hook-Face Pad.

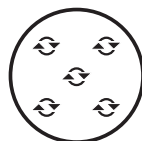

**Orbital Motion**

Model Number	Motor RPM	Sound Level	Maximum Air Flow SCFM (L/Min)	Hose I.D. Size Inch (mm)	Air Inlet Thread	Weight Pound (kg)	Length Inch (mm)	Height Inch (mm)
57920	20,000	68 dB(A)	9 (255)	1/4 (6)	1/4" NPT	1 (.45)	5 (127)	3 (76)
57923	20,000	68 dB(A)	9 (255)	1/4 (6)	1/4" NPT	1 (.5)	5-1/2 (140)	3 (76)
57925	20,000	68 dB(A)	9 (255)	1/4 (6)	1/4" NPT	1 (.5)	5 (127)	3 (76)
57922	20,000	68 dB(A)	9 (255)	1/4 (6)	1/4" NPT	1 (.5)	5-1/2 (140)	3 (76)
57924	20,000	68 dB(A)	9 (255)	1/4 (6)	1/4" NPT	1 (.5)	5-1/2 (140)	3 (76)
57926	20,000	68 dB(A)	9 (255)	1/4 (6)	1/4" NPT	1 (.5)	5 (127)	3 (76)
57927	20,000	68 dB(A)	9 (255)	1/4 (6)	1/4" NPT	1 (.5)	5 (127)	3 (76)

Tune-Up Kit: No. 96169 (page 267) • Additional Specifications: Air Pressure 90 PSIG (6.2 Bar)