

EZR Rack



Specifications


EZR Rack



The compact design, adjustability, durable construction and attractive chrome finish makes the EZ rack ideal for a host of on-floor and backroom applications. The top hang bar extends up to 72" to hold larger volumes of merchandise. Racks nest to save space when not in use.

- EZR-250K2 upgrades 2 casters to total-lock brakes
- 40"L x 24"W x 56" – 73"H (adjustable)
- Attractive lacquered zinc
- 1,000 lb. load capacity
- Disassembles in seconds - no tools required
- Ships K.D. - easy assembly

Model # EZR-250KS

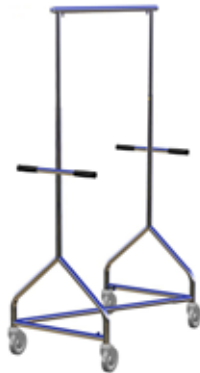

EZ Rack

Model #	Width		Length (Base)		Overall Height		Description
	(in.)	(mm)	(in.)	(mm)	(in.)	(mm)	
EZR--LZ-250K2	24	610	Adj. 40 - 72	Adj. 1016 - 1829	Adj. 56 - 73	Adj. 1422 - 1854	EZ Rack w/2 total-lock

Additional catalogue sheets are available on our web site: www.irsg.com



IRSG
1383 Hamilton Parkway
Itasca, IL 60143
Phone: (800) 822-4264 • Fax: (630) 773-7137

For custom design, configuration or fabrication, please call (888) 598-2001 or e-mail us at info.irsg.com

IRSG For product information, call 1-888-598-2001

Every attempt has been made to ensure the accuracy of the product information. We cannot be held responsible for printing or typographical errors. Please confirm product information a time of order; information is subject to change without notice