




- G1806** Eyewash, Deck Mounted, 90° Swivel, Right Hand Mounting
- G1806LH** Eyewash, Deck Mounted, 90° Swivel, Left Hand Mounting

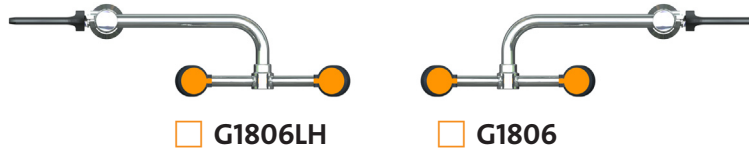

**Application:** Eyewash for mounting on counter next to sink. Spray heads swivel 90 degrees from storage to operational position. Water flow is activated by flag handle.

**Spray Head Assembly:** Two GS-Plus™ spray heads. Each head has a “flip top” dust cover, internal flow control and filter to remove impurities from the water flow.

**Valve:** 1/2" IPS chrome plated brass stay-open ball valve. Valve is US-made with chrome plated brass ball and Teflon® seals.

**Mounting:** Unit may be mounted on right side (G1806) or left side (G1806LH) of sink. Furnished with locknut and washer for securing unit to countertop.

**Construction:** Polished chrome plated brass.

**Supply:** 1/2" NPT male inlet.

**Sign:** ANSI-compliant identification sign.


**Quality Assurance:** Unit is completely assembled and water tested prior to shipment.

### Available Options

- DC** Stainless steel dust cover for each spray head.
- TMV** G3600 thermostatic mixing valve precisely blends hot and cold water to deliver warm (tepid) water as required by ANSI Z358.1-2009. Refer to “Tempering Units” section for complete technical and product selection information.



- **G1806** Eyewash, Deck Mounted, 90° Swivel, Right Hand Mounting
- **G1806LH** Eyewash, Deck Mounted, 90° Swivel, Left Hand Mounting

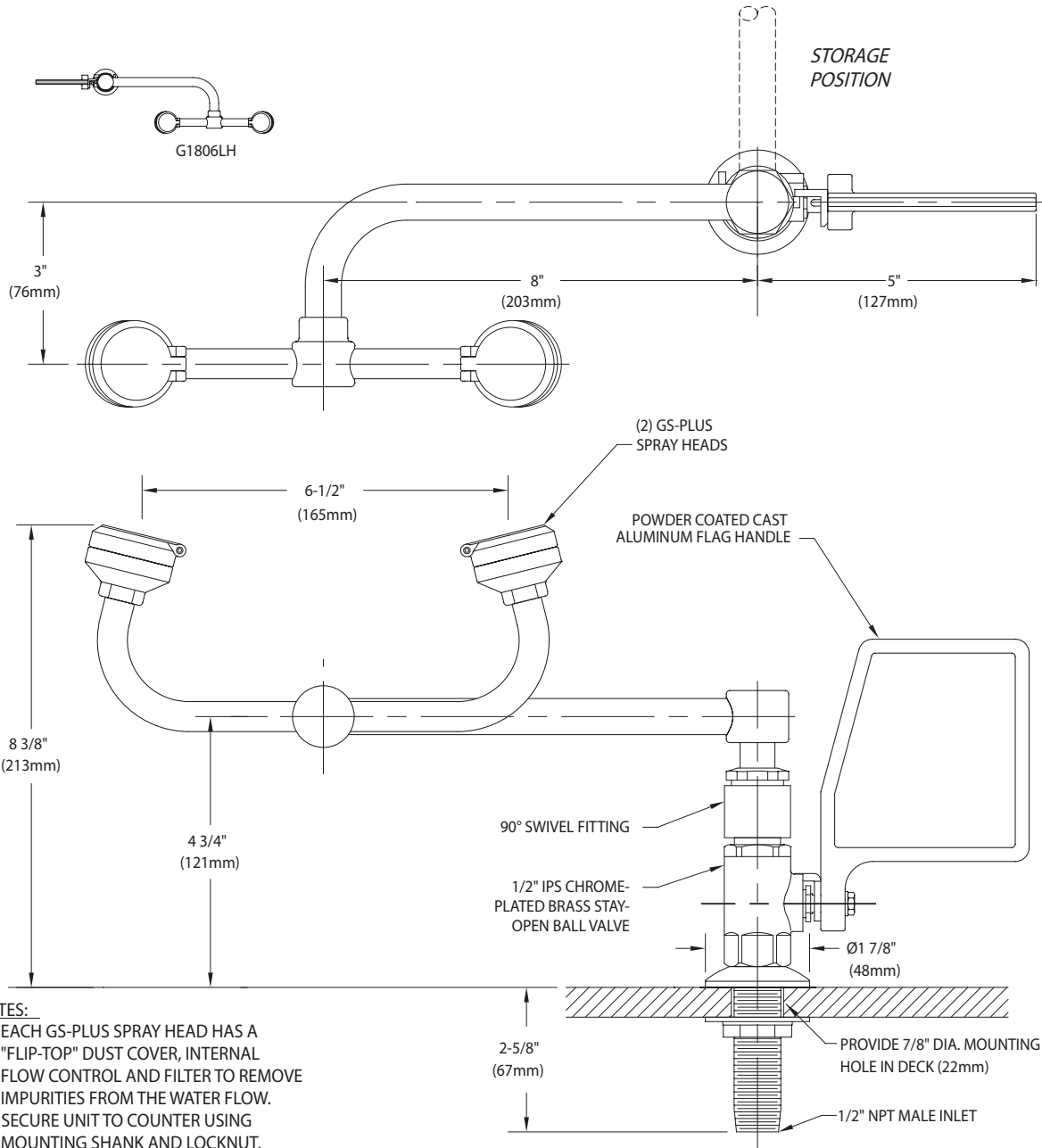

THIS SPACE FOR ARCHITECT/ENGINEER APPROVAL

Due to continuing product improvement, the information contained in this document is subject to change without notice. All dimensions are ± 1/4" (6mm). rev. 0114

Sign Included

