



Item	Part Number	Description
A	AP450-048	10" Dia. Stainless Steel Shower Head
B	320-08E	1" IPS Stainless Steel Elbow

Shower Valve Assembly		
C	AP620-335H	1" IPS Stainless Steel Stay-Open Ball Valve, Single Activation. Furnished with stainless steel actuating arm.


Pipe Packs		
D	AP520-100	Stainless Steel Pipe Pack for Units with Eyewash Bowl
	AP520-170	Stainless Steel Pipe Pack for Barrier-Free Units
	AP530-100	Orange Pipe Covers

Eyewash Valve Assemblies		
E	AP620-101H	1/2" IPS Stainless Steel Ball Valve with Stainless Steel Flag Handle
	AP620-101H-HFC	1/2" IPS Stainless Steel Ball Valve with Stainless Steel Flag Handle for Units with Hand/Foot Control

F	320-10F	Stainless Steel Floor Flange, 1 1/4" NPT Female Connection
G	AP050-010SS	Stainless Steel Foot Treadle and Return Spring with Aluminum Clevis Pin
H	See Page 2	Eyewash and Eye/Face Wash Assemblies

Shower Pull Rods		
I	AP050-079	29" Stainless Steel Pull Rod
	AP050-080	47 1/2" Stainless Steel Pull Rod


Sign		
J	AP250-008G	Emergency Safety Station Sign

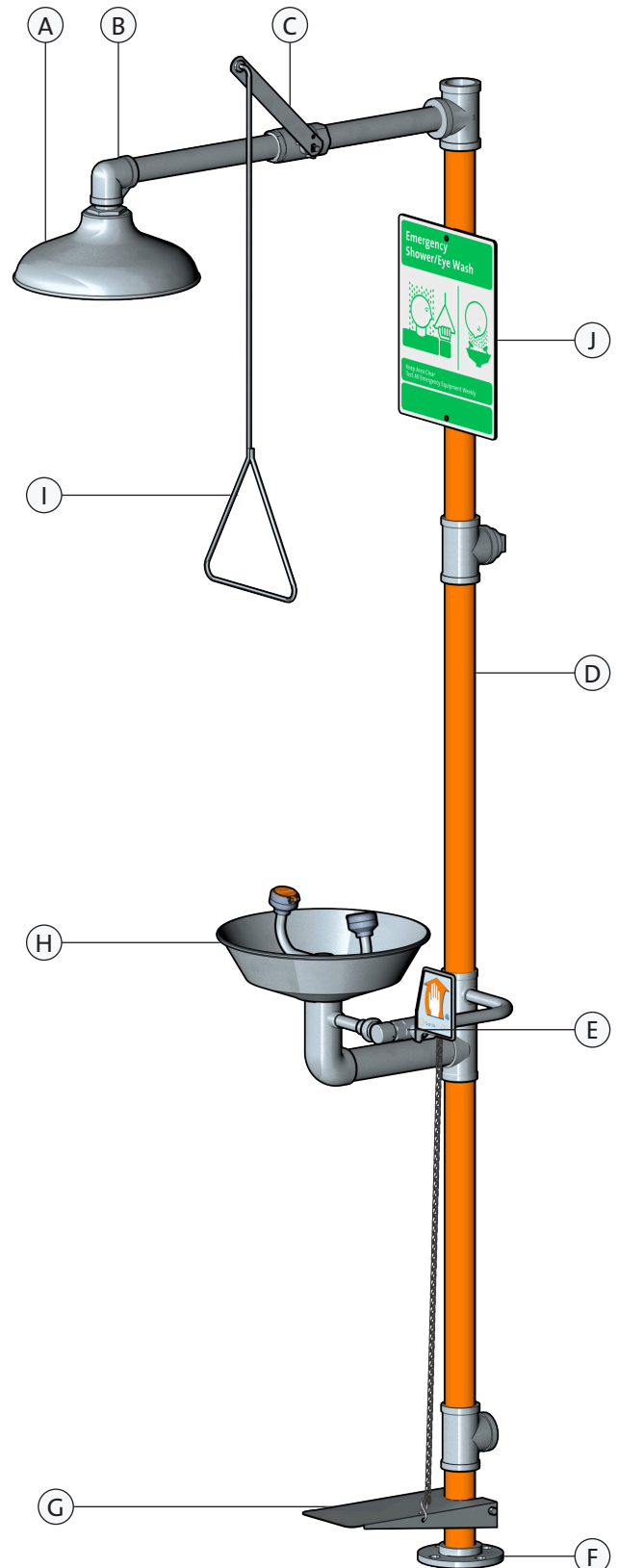



Item	Part Number	Description
Spray Head Dust Covers		
A	470-001	GS-Plus™ Spray Head Assy.
	470-021	FS-Plus™ Spray Head Assy.
Outlet Assemblies		
B	AP470-100SS-R	(2) GS-Plus™ Spray Heads with Stainless Steel Fittings
	AP470-110SS-R	(2) FS-Plus™ Spray Heads with Stainless Steel Fittings
	AP470-120SS-R	(4) GS-Plus™ Spray Heads with Stainless Steel Fittings
	AP470-127SS-R	(4) GS-Plus™ Spray Heads with Stainless Steel Fittings for Barrier-Free Units
C	SI130-02-04	3/8" IPS X 2-1/4" Stainless Steel Shank

Item	Part Number	Description
Bowls		
D	100-008R	Stainless Steel Bowl
	100-014R	Stainless Steel Bowl for Barrier-Free Units
	100-008X	Stainless Steel Bowl with Neck
	100-014X	Stainless Steel Bowl with Neck for Barrier-Free Units
Drain Plate Assemblies		
E	AP150-012A	Drain Plate Assembly for Plastic Bowls
	AP150-012B	Drain Plate Assembly for Stainless Bowls
<i>Note: Includes Drain Plate, Cupped Washer, And Gasket</i>		

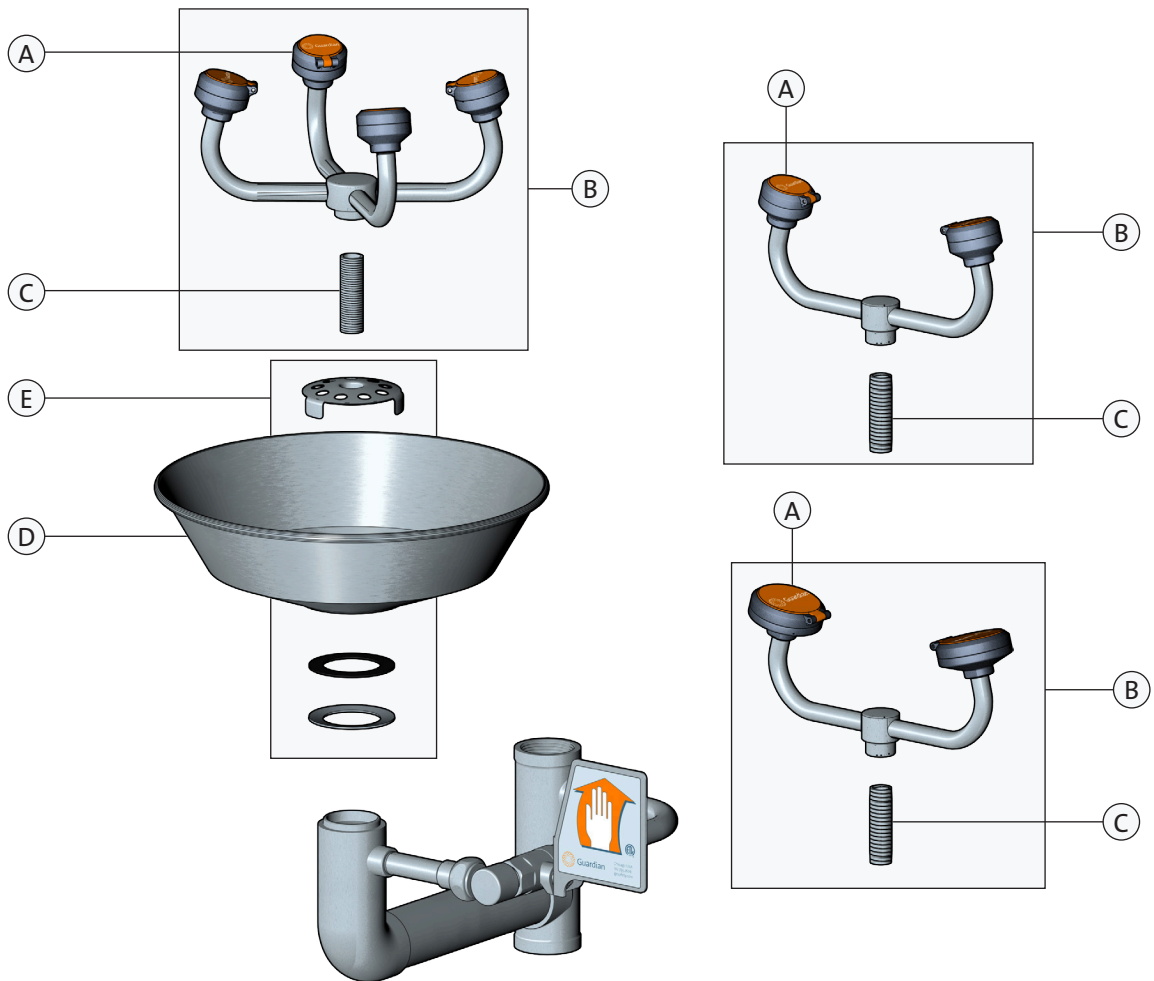



Each spray head features:

- Tough polypropylene plastic construction
- Highly visible integrated nylon dust cover
- Easily accessible 1.8 GPM (GS-Plus™) or 3.2 GPM (FS-Plus™) flow controls.
- Dense (60 pore per inch) polyurethane filter
- Unique design provides a consistently soft, full spray of water across a range of working pressures from 30 to 100 PSI

Item	Part Number	Description
A	AP470-001	GS-Plus™ Spray Head (assembled)
B	AP470-002R	Dust Cover and Cap Assembly
C	470-004R	60 PPI Polyurethane Filter
D	470-005R	1.8 GPM Flow Control
E	AP470-021	FS-Plus™ Spray Head (assembled)
F	AP470-022R	Dust Cover and Cap Assembly
G	470-024R	60 PPI Polyurethane Filter
H	470-025R	3.2 GPM Flow Control

