

YES WE CAN!

With Piano Hinge

HALLOWELL PREMIUM™ BOX LOCKERS

Louvered doors and are ideal for storing personal items.



Six Tier,
3 wide,
18 openings



Six Tier,
1 wide,
6 openings



Five Tier,
1 wide,
5 openings



Six Tier,
3 wide,
18 openings




Six Tier,
1 wide,
6 openings



Five Tier,
1 wide,
5 openings



4-wide Wall Mount

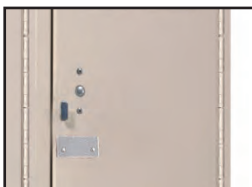

Single-point thru-the-door friction catch door pull designed for use with a padlock or built-in lock. Shown with optional strike plate which protects door from being marred by padlock



Sixteen-Person Lockers

GREAT SERVICE = GREAT RESULTS



A Tradition of Quality Since 1903

FEATURES:

BODY CONSTRUCTION: Knock-down, 24 gauge
BODY STYLES: Five tier, six tier and 16 Person
DOOR: 18 gauge Louvered for added ventilation
HINGES: Continuous piano type
HANDLE: Single-point projecting friction catch door pull prepared for both padlock or built-in lock. No moving parts insures quiet maintenance-free operation.
HOOKS: None
COAT RODS: None
SHELVES: None
LEGS: 6" high legs are standard. Lockers without legs are available for a nominal charge
APPEARANCE: Parchment and Hallowell Gray. Lockers include matching body colors. Order Finished End Panels for exposed row ends if desired. Finished End Panels install over top of universal side panels adding strength and rigidity at exposed row ends and can be ordered to match locker door/frame color.

GENERAL FEATURES:

- Lockers can be ordered fully-assembled or knock-down for assembly at destination.
- Order 3-wide units for best value. Order 1-wide units to complete quantity needed for each continuous row.
- Lockers can be ordered in combination with Premium wardrobe lockers.
- Locks are not included.

Locker Type	Overall Dimensions (In.)			Opening Dimensions (In.)			Knock-Down		Fully-Assembled		Shpg Wt
	W	H	D	W	H	D	Item No. Parchment	Item No. Hallowell Gray	Item No. Parchment	Item No. Hallowell Gray	
FIVE TIER WITH LEGS											
1 wide, 5 openings	12	66	12	9 1/4	10 1/2	11	4VEU3	4VEU1	4VEV6	4VEV4	53
3 wide, 15 openings	36	66	12	9 1/4	10 1/2	11	4VEU4	4VEU2	4VEV7	4VEV5	149
1 wide, 5 openings	12	66	15	9 1/4	10 1/2	14	4VEU7	4VEU5	4VEW1	4VEV8	59
1 wide, 15 openings	36	66	15	9 1/4	10 1/2	14	4VEU8	4VEU6	4VEW2	4VEV9	165
1 wide, 5 openings	12	66	18	9 1/4	10 1/2	17	4VEV2	4VEU9	4VEW5	4VEW3	65
3 wide, 15 openings	36	66	18	9 1/4	10 1/2	17	4VEV3	4VEV1	4VEW6	4VEW4	179
SIX TIER WITH LEGS											
1 wide, 6 opening	12	78	12	9-1/4	10-1/2	11	4HE19	4HE25	4HE31	4HE37	59
3 wide, 18 openings	36	78	12	9-1/4	10-1/2	11	4HE20	4HE26	4HE32	4HE38	165
1 wide, 6 opening	12	78	15	9-1/4	10-1/2	14	4HE21	4HE27	4HE33	4HE39	63
3 wide, 18 openings	36	78	15	9-1/4	10-1/2	14	4HE22	4HE28	4HE34	4HE40	174
1 wide, 6 opening	12	78	18	9-1/4	10-1/2	17	4HE23	4HE29	4HE35	4HE41	66
3 wide, 18 openings	36	78	18	9-1/4	10-1/2	17	4HE24	4HE30	4HE36	4HE42	180
SIXTEEN PERSON WITH LEGS											
16 openings	72	78	18	9-1/4	10-1/2	17	4HE43	4HE44	4HE45	4HE46	228
3 WIDE WALL MOUNT											
4 openings	48	14-3/4	18	9-1/4	10-1/2	17	4VEW8	4VEW7	4VEX1	4VEW9	50

COLOR SELECTION

729
PARCHMENT (PT)

725
HALLOWELL GRAY (HG)

GREAT SERVICE = GREAT RESULTS