

# YES!

WE CAN!

With Piano Hinge

- ✓ Ventilated doors and sides
- ✓ Heavy gauge door and body
- ✓ Large capacity sizes available
- ✓ Strength and ventilation in one practical locker

**FEATURES:**

**BODY CONSTRUCTION:** Knock-down, 16 gauge body with 18 gauge back. Sides are diamond perforated for maximum ventilation

**BODY STYLES:** Single, double, triple and six tier

**DOOR:** 14 gauge, diamond perforated

**HINGES:** Continuous piano type

**HANDLE (wardrobe):** Stainless steel recessed handle with multi-point gravity lift-type latching. Recessed handle protects finish from being marred by padlock.


**HANDLE (box):** Box lockers include a projecting single-point friction catch door pull prepared for both padlock or built-in lock. No moving parts insures quiet maintenance-free operation.

**HOOKS:** One double prong ceiling hook and two single hooks per single and double tier opening. One double ceiling hook for triple tier. No hooks for six tier

**COAT RODS:** Available for single tier at a nominal cost

**SHELVES:** Hat shelf is included in single tier lockers.

**LEGS:** 6" high legs are standard. Lockers without legs are available for a nominal charge

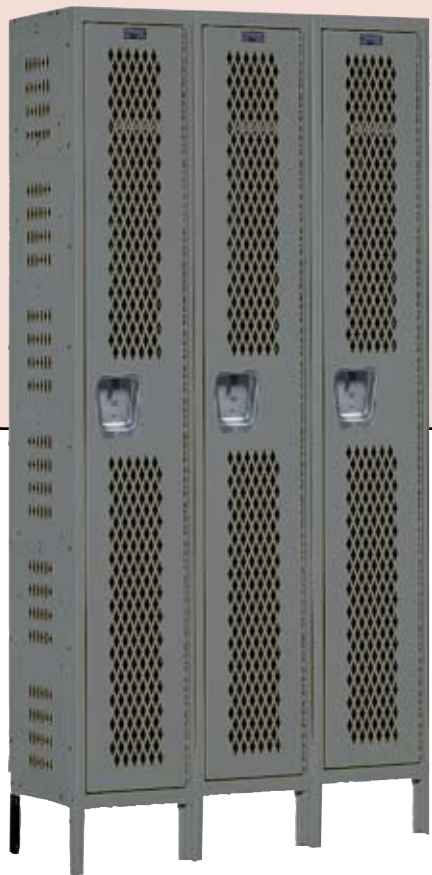

Single Tier,  
3 wide,  
3 openings



Double Tier,  
3 wide,  
6 opening



Six Tier,  
1 wide,  
6 openings



Single Tier,  
1 wide,  
1 opening





**Heavy-Duty Ventilated (HDV) KD Stock Lockers**



Single Tier,  
1 wide,  
1 opening



Double Tier,  
1 wide,  
2 openings



Single Tier,  
1 wide,  
1 opening

Locker Type	Overall Dimensions (In.)			Opening Dimensions (In.)			Weight	Knock-Down Hallowell Gray Item No.	Fully-Assembled Hallowell Gray Item No.
	W	H	D	W	H	D			
<b>SINGLE TIER</b>									
1 wide, 1 opening	12	78	12	9-1/4	69	11	80	4VEH2	4VEK2
3 wide, 3 openings	36	78	12	9-1/4	69	11	210	4VEH3	4VEK3
1 wide, 1 opening	12	78	15	9-1/4	69	14	89	4VEH4	4VEK4
3 wide, 3 openings	36	78	15	9-1/4	69	14	229	4VEH5	4VEK5
1 wide, 1 opening	12	78	18	9-1/4	69	17	62	4HE63	4HE71
3 wide, 3 openings	36	78	18	9-1/4	69	17	145	4HE64	4HE72
1 wide, 1 opening	15	78	15	12-1/4	69	14	99	4VEH6	4VEK6
3 wide, 3 openings	45	78	15	12-1/4	69	14	259	4VEH7	4VEK7
1 wide, 1 opening	15	78	18	12-1/4	69	17	56	4HE65	4HE73
3 wide, 3 openings	45	78	18	12-1/4	69	17	156	4HE66	4HE74
1 wide, 1 opening	18	78	18	15-1/4	69	17	61	4HE67	4HE75
3 wide, 3 openings	54	78	18	15-1/4	69	17	167	4HE68	4HE76
1 wide, 1 opening	18	78	21	15-1/4	69	20	64	4HE69	4HE77
3 wide, 3 openings	54	78	21	15-1/4	69	20	174	4HE70	4HE78
<b>DOUBLE TIER</b>									
1 wide, 2 openings	12	78	12	9-1/4	34	11	82	4VEH8	4VEK8
3 wide, 6 openings	36	78	12	9-1/4	34	11	216	4VEH9	4VEK9
1 wide, 2 openings	12	78	15	9-1/4	34	14	91	4VEJ1	4VEL1
3 wide, 6 openings	36	78	15	9-1/4	34	14	235	4VEJ2	4VEL2
1 wide, 2 openings	12	78	18	9-1/4	34	17	66	4HE79	4HE85
3 wide, 6 openings	36	78	18	9 1/4	34	17	180	4HE80	4HE86
1 wide, 2 openings	15	78	15	12-1/4	34	14	101	4VEJ3	4VEL3
3 wide, 6 openings	45	78	15	12-1/4	34	14	265	4VEJ4	4VEL4
1 wide, 2 openings	15	78	18	12-1/4	34	17	56	4HE81	4HE87
3 wide, 6 openings	45	78	18	12-1/4	34	17	156	4HE82	4HE88
1 wide, 2 openings	18	78	18	15-1/4	34	17	61	4HE83	4HE89
3 wide, 6 openings	54	78	18	15-1/4	34	17	156	4HE84	4HE90
1 wide, 2 openings	18	78	21	15-1/4	34	20	134	4VEJ5	4VEL5
3 wide, 6 openings	54	78	21	15-1/4	34	20	350	4VEJ6	4VEL6
<b>SIX TIER</b>									
1 wide, 6 openings	12	78	12	9-1/4	10-1/2	11	94	4VEJ7	4VEL7
3 wide, 18 openings	36	78	12	9-1/4	10-1/2	11	252	4VEJ8	4VEL8
1 wide, 6 openings	12	78	15	9-1/4	10-1/2	14	109	4VEJ9	4VEL9
3 wide, 18 openings	36	78	15	9-1/4	10-1/2	14	289	4VEK1	4VEN1
1 wide, 6 openings	12	78	18	9-1/4	10-1/2	17	64	4HE91	4HE93
3 wide, 18 openings	36	78	18	9-1/4	10-1/2	17	174	4HE92	4HE94