

# YES!

WE CAN!

## OPEN SHELVING



**Hi-Tech® Industrial grade steel shelving continues a tradition of quality** established generations ago with the goal of providing a shelving line with the strength needed to handle most industrial applications and versatility for today's modern facilities.

Our complete line of shelving is designed and engineered to the highest standards. A full complement of accessories including full dividers, partial dividers, label holders, swinging doors, post splices for multilevel installations and foot plates are available to complete your system.



Box beam adjustable shelves

**An innovative Hi-Tech design and specially designed components allow for a fast and easy assembly.**

### BEADED FRONT POSTS

- Beaded for strength
- Flush to permit straight-in/ straight-out shelf installation, shelf changing and shelf loading. No tilting needed
- Get the full use of shelf area
- Punched on 1-1/2" centers to allow positioning of one shelf independent of other shelves

### ANGLE BACK POSTS AND T-POSTS

- Roll formed into a unique angle shape for maximum strength
- The long leg is punched on 1-1/2" centers to allow independent shelf adjustment
- Angle Posts can be used in place of Beaded Front Posts if desired

COLOR SELECTION

725 HALLOWELL GRAY (HG)




# CLOSED SHELVING



**STARTER UNITS**

**ADDER UNITS**

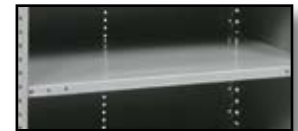

Box beam adjustable shelves



Base strip closes bottom. Used to prevent debris accumulation



Swinging doors allow cabinet-style storage



Shelf dividers for organized storage



## HEAVY DUTY SHELVES

- Tubular welded box beam front and rear for maximum strength
- Exclusive triple bend side flanges for added strength
- Lapped and welded corners
- Top of shelf is punched to accept shelf dividers
- Uses four one piece shelf clips per shelf
- Can be installed together with both Beaded Front and Angle Back Posts as well as T-Posts and H-Posts



## ONE PIECE SHELF CLIP

- Each shelf requires four of these sturdy and compact clips
- Clips key firmly into post slots to hold shelves securely in place
- Fits Beaded Front, Angle Back Posts and T-Posts
- Provides independent shelf positioning on 1-1/2" centers
- Non-Intrusive clip sits flush with inside edge of front posts

# YES!

## WE CAN!

### OPEN SHELVING MEDIUM, HEAVY AND EXTRA HEAVY-DUTY



STARTER UNIT



ADDER UNIT



5 SHELVES UNIT



6 SHELVES UNIT



8 SHELVES UNIT

W	H	D		Shelf Capacity	5-Adj Shelf Unit SKU no.	W/lbs	6-Adj Shelf Unit SKU No.	W/lbs	8-Adj Shelf Unit SKU No.	W/lbs
<b>MEDIUM-DUTY</b>										
36	87	12	Starter	500*	1BFL8	69	1BGL2	76	1BGL5	89
36	87	12	Adder	500*	1BHL8	59	1BJL1	65	1BJL4	78
36	87	18	Starter	500*	1BFL9	80	1BGL3	89	1BGL6	106
36	87	18	Adder	500*	1BHL9	70	1BJL2	78	1BJL5	95
36	87	24	Starter	500*	1BGL1	92	1BGL4	102	1BGL7	124
36	87	24	Adder	500*	1BHV8	80	1BJL3	91	1BJL6	113
48	87	12	Starter	375*	1BGL8	82	1BHL2	90	1BHL5	108
48	87	12	Adder	375*	1BJL7	71	1BKL1	80	1BKL4	498
48	87	18	Starter	375*	1BGL9	95	1BHL3	107	1BHL6	130
48	87	18	Adder	375*	1BJL8	84	1BKL2	96	1BKL5	119
48	87	24	Starter	350*	1BHL1	109	1BHL4	123	1BHL7	151
48	87	24	Adder	350*	1BJL9	98	1BKL3	112	1BKL6	140
<b>HEAVY-DUTY</b>										
36	87	12	Starter	800*	1BKL7	76	1BLA1	83	1BLA4	99
36	87	12	Adder	800*	1BLB7	65	1BLC1	73	1BLC4	89
36	87	18	Starter	800*	1BKL8	89	1BLA2	99	1BLA5	120
36	87	18	Adder	800*	1BLB8	78	1BLC2	88	1BLC5	109
36	87	24	Starter	800*	1BKL9	102	1BLA3	115	1BLA6	141
36	87	24	Adder	800*	1BLB9	91	1BLC3	104	1BLC6	129
48	87	12	Starter	400*	1BLA7	86	1BLB1	98	1BLB4	119
48	87	12	Adder	400*	1BLC7	81	1BLD1	88	1BLD4	108
48	87	18	Starter	450*	1BLA8	105	1BLB2	118	1BLB5	145
48	87	18	Adder	450*	1BLC8	94	1BLD2	107	1BLD5	134
48	87	24	Starter	500*	1BLA9	122	1BLB3	138	1BLB6	171
48	87	24	Adder	500*	1BLC9	110	1BLD3	127	1BLD6	160
<b>EXTRA HEAVY-DUTY DUTY</b>										
36	87	12	Starter	1100*	1BLD7	89	1BLE1	99	1BLE4	120
36	87	12	Adder	1100*	1BLF7	78	1BLG1	89	1BLG4	109
36	87	18	Starter	1200*	1BLD8	106	1BLE2	120	1BLE5	147
36	87	18	Adder	1200*	1BLF8	95	1BLG2	109	1BLG5	136
36	87	24	Starter	1250*	1BLD9	124	1BLE3	141	1BLE6	175
36	87	24	Adder	1250*	1BLF9	112	1BLG3	130	1BLG6	164
48	87	12	Starter	750*	1BLE7	105	1BLF1	119	1BLF4	146
48	87	12	Adder	750*	1BLG7	96	1BLH1	108	1BLH4	135
48	87	18	Starter	900*	1BLE8	127	1BLF2	145	1BLF5	181
48	87	18	Adder	900*	1BLG8	116	1BLH2	134	1BLH5	170
48	87	24	Starter	900*	1BLE9	150	1BLF3	172	1BLF6	216
48	87	24	Adder	900*	1BLG9	138	1BLH3	161	1BLH7	205
<b>ADDITIONAL SHELVES</b>					<b>Medium-Duty</b>		<b>Heavy-Duty</b>		<b>Extra Heavy-Duty</b>	
36		12			1BNL4	33	1BPL1	39	1PBL7	52
36		18			1BNL5	43	1BPL2	52	1PBL8	69
36		24			1BNL6	54	1BPL3	64	1PBL9	86
48		12			1BNL7	45	1BPL4	51	1BRL1	68
48		18			1BNL8	58	1BPL5	67	1BRL2	90
48		24			1BNL9	71	1BPL6	83	1BRL3	111

NOTES: Color for all components 725 Hallowell Gray.

\*Safety factor=1.65

**OPEN UNITS:** Starter units include two beaded front posts, two angle back posts, one pair back sway braces, two pair side sway braces and 5-8 shelves. Adder units include one beaded front post, two angle back posts, one pair back sway braces, one pair side sway braces and 5-8 shelves. \* Safety factor=1.65

COLOR SELECTION

725 HALLOWELL GRAY (HG)

## CLOSED SHELVING MEDIUM, HEAVY AND EXTRA HEAVY-DUTY

W	H	D		Shelf Capacity	5-Adj Shelf Unit SKU No.	W/lbs	6-Adj Shelf Unit SKU No.	W/lbs	8-Adj Shelf Unit SKU No.	W/lbs
<b>MEDIUM-DUTY</b>										
36	87	12	Starter	500*	1BLH9	95	1BLJ6	102	1BLK1	115
36	87	12	Adder	500*	1BLN2	81	1BLN8	87	1BLP5	100
36	87	18	Starter	500*	1BLJ2	113	1BLJ8	122	1BLK2	139
36	87	18	Adder	500*	1BLN4	95	1BLP1	103	1BLP7	120
36	87	24	Starter	500*	1BLJ4	131	1BLJ9	141	1BLK3	163
36	87	24	Adder	500*	1BLN6	109	1BLP3	119	1BLP9	141
48	87	12	Starter	375*	1BLK4	115	1BLK8	123	1BLL5	141
48	87	12	Adder	375*	1BLR2	100	1BLR7	109	1BLT1	127
48	87	18	Starter	375*	1BLK5	135	1BLL1	146	1BLL7	169
48	87	18	Adder	375*	1BLR4	116	1BLR8	128	1BLT2	151
48	87	24	Starter	350*	1BLK6	155	1BLL3	169	1BLL9	197
48	87	24	Adder	350*	1BLR6	133	1BLR9	147	1BLT3	175
<b>HEAVY-DUTY</b>										
36	87	12	Starter	800*	1BLT4	102	1BLT7	110	1BLU1	125
36	87	12	Adder	800*	1BLV4	87	1BLV7	95	1BLW1	110
36	87	18	Starter	800*	1BLT5	121	1BLT8	132	1BLU2	152
36	87	18	Adder	800*	1BLV5	103	1BLV8	113	1BLW2	134
36	87	24	Starter	800*	1BLT6	141	1BLT9	154	1BLU3	180
36	87	24	Adder	800*	1BLV6	119	1BLV9	132	1BLW3	158
48	87	12	Starter	400*	1BLU4	121	1BLU7	131	1BLV1	152
48	87	12	Adder	400*	1BLW4	106	1BLW7	117	1BLX1	137
48	87	18	Starter	450*	1BLU5	144	1BLU8	158	1BLV2	184
48	87	18	Adder	450*	1BLW5	126	1BLW8	139	1BLX2	166
48	87	24	Starter	500*	1BLU6	167	1BLU9	184	1BLV3	217
48	87	24	Adder	500*	1BLW6	146	1BLW9	162	1BLX3	195
<b>EXTRA HEAVY-DUTY DUTY</b>										
36	87	12	Starter	1100*	1BLX4	115	1BLX7	125	1BLY1	146
36	87	12	Adder	1100*	1BLZ4	100	1BLZ7	110	1BML1	131
36	87	18	Starter	1200*	1BLX5	138	1BLX8	152	1BLY2	180
36	87	18	Adder	1200*	1BLZ5	120	1BLZ8	134	1BML3	161
36	87	24	Starter	1250*	1BLX6	163	1BLX9	180	1BLY3	214
36	87	24	Adder	1250*	1BLZ6	141	1BLZ9	158	1BML3	192
48	87	12	Starter	750*	1BLY4	138	1BLY7	152	1BLZ1	179
48	87	12	Adder	750*	1BML4	123	1BML7	137	1BNL1	164
48	87	18	Starter	900*	1BLY5	167	1BLY8	185	1BLZ2	220
48	87	18	Adder	900*	1BML5	148	1BML8	166	1BNL2	202
48	87	24	Starter	900*	1BLY6	195	1BLY9	218	1BLZ3	262
48	87	24	Adder	900*	1BML6	174	1BML9	196	1BNL3	240
<b>ADDITIONAL SHELVES</b>					<b>Medium-Duty</b>		<b>Heavy-Duty</b>		<b>Extra Heavy-Duty</b>	
36		12	See Above		1BNL4	33	1BPL1	39	1PBL7	52
36		18	See Above		1BNL5	43	1BPL2	52	1PBL8	69
36		24	See Above		1BNL6	54	1BPL3	64	1PBL9	86
48		12	See Above		1BNL7	45	1BPL4	51	1BRL1	68
48		18	See Above		1BNL8	58	1BPL5	67	1BRL2	90
48		24	See Above		1BNL9	71	1BPL6	83	1BRL3	111

Vertical Shelf Dividers (Pkg. of 12)			Double Swinging doors		
D	H	Item No.	W	H	Item No.
12	6	1BRL4	36	84	1BTL4
12	9	1BRL5	48	84	1BTL5
12	12	1BRL6	<b>Closed Base Strips (Pkg. of 10)</b>		
18	6	1BRL7			
18	9	1BRL8	36	3	1BTL6
18	12	1BRL9	48	3	1BTL7
24	6	1BTL1			
24	9	1BTL2			
24	12	1BTL3			

**NOTES:**  
 Color for all components 725 Hallowell Gray.  
 \*Safety factor=1.65

**CLOSED UNITS:** Starter units include two beaded front posts, two angle back posts, one back panel assembly, two side panel assemblies and 5-8 shelves.

Adder units include one beaded front post, two angle back posts, one back panel assembly, one side panel assembly and 5-8 shelves.



STARTER UNIT



ADDER UNIT



5 SHELVES UNIT



6 SHELVES UNIT



8 SHELVES UNIT