

YES!

WE CAN!



HALLOWELL® Hybrid

THE PRESTIGE OF FINE WOOD, THE AFFORDABLE PRICE OF KD LOCKERS

FEATURES:

BODY CONSTRUCTION: Knock-down, 24 gauge sheet steel

BODY STYLES: Single, double and triple tier

DOOR: Furniture grade solid red oak plywood, finished with 3 coats of lacquer

HINGES: Continuous piano type

HOOKS: Two single hooks per single and double tier opening. One double prong ceiling hook for triple tier.

COAT RODS: Standard for single and double tier **SHELVES:** Hat shelf in single tier lockers only.

LEGS: 6" high legs are standard. Lockers without legs are available at a nominal charge legs

APPEARANCE: Color: black frame with red oak doors.



Single tier,
3 wide

Includes
Key Lock




Double tier,
1 wide



Triple tier,
3 wide

All lockers shown with optional closed metal base.

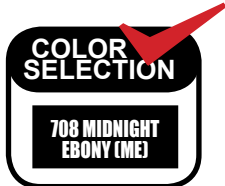

Locker Type	Overall Dimensions (In.)			Opening Dimensions (In.)			Knock-down Cat. No.	Fully Assembled Cat. No.	Color Selection	Wt.
	W	H	D	W	H	D				
SINGLE TIER										
1 wide, 1 opening	12	78	18	9-1/4	69	17	4VEN2	4VEP3	ME/Red Oak	93
3 wide, 3 openings	36	78	18	9-1/4	69	17	4VEN3	4VEP4	ME/Red Oak	252
1 wide, 1 opening	15	78	18	12-1/4	69	17	4VEN4	4VEP5	ME/Red Oak	104
3 wide, 3 openings	45	78	18	12-1/4	69	17	4VEN5	4VEP6	ME/Red Oak	284
DOUBLE TIER										
1 wide, 2 openings	12	78	18	9-1/4	34	17	4VEN6	4VEP7	ME/Red Oak	96
3 wide, 6 openings	36	78	18	9-1/4	34	17	4VEN7	4VEP8	ME/Red Oak	261
1 wide, 2 openings	15	78	18	12-1/4	34	17	4VEN8	4VEP9	ME/Red Oak	108
3 wide, 6 openings	45	78	18	12-1/4	34	17	4VEN9	4VER1	ME/Red Oak	297
TRIPLE TIER										
1 wide, 3 openings	12	78	18	9-1/4	22-1/4	17	4VEP1	4VER2	ME/Red Oak	99
3 wide, 9 openings	36	78	18	9-1/4	22-1/4	17	4VEP2	4VER3	ME/Red Oak	270