

YES!

WE CAN!

With Piano
Hinge



Single Tier,
1 wide,
1 opening



Double Tier,
1 wide,
2 openings



Triple Tier,
1 wide,
3 openings

Modern flush door design with safety-minded handle and reinforced door make our Maintenance-Free Quiet™ KD stock lockers the smart choice.

FEATURES:

BODY CONSTRUCTION: Knock-down, 24 gauge

BODY STYLES: Single, double and triple tiers

DOOR: 16 gauge, solid with welded on door stiffener

HINGES: Continuous piano type

HANDLE: Deep drawn stainless steel recessed handle with single-point latching. Recessed handle protects finish from being marred by padlock.

HOOKS: One double prong ceiling hook and two single hooks per single and double tier opening. One double ceiling hook for triple tier.

COAT RODS: Available for single tier at a nominal cost

SHELVES: Hat shelf is included in single tier lockers.

LEGS: 6" high legs are standard. Lockers without legs are available for a nominal charge

COLOR
SELECTION

729
PARCHMENT (PT)

725
HALLOWELL GRAY (HG)

A Tradition of Quality Since 1903




**Single Tier,
3 wide,
3 openings**



**Triple Tier,
3 wide,
9 openings**



Deep-drawn stainless steel recessed handle with single-point latching

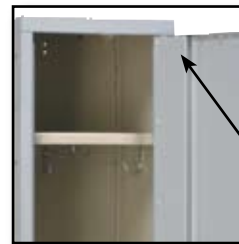

Maintenance-Free Quiet Lockers include a 3" wide 18 gauge full height door stiffener spot welded to the inner door face and MIG welded to the hinge side as well as to the top and bottom door flanges providing a rigid torque-free door.

| Locker Type | Overall Dimensions (In.) | | | Opening Dimensions (In.) | | | Knock-Down | | | Fully-Assembled | | |
|------------------------------|--------------------------|----|----|--------------------------|--------|----|--------------------|---------------|---------|--------------------|---------------|---------|
| | W | H | D | W | H | D | Item No. Parchment | Item No. Gray | Shpg Wt | Item No. Parchment | Item No. Gray | Shpg Wt |
| SINGLE TIER WITH LEGS | | | | | | | | | | | | |
| 1 wide, 1 opening | 12 | 78 | 12 | 9-1/4 | 69 | 11 | 2PFW3 | 2PFZ8 | 59 | 2PGF4 | 2PGJ9 | 59 |
| 3 wide, 3 openings | 36 | 78 | 12 | 9-1/4 | 69 | 11 | 2PFW4 | 2PFZ9 | 165 | 2PGF5 | 2PGK1 | 165 |
| 1 wide, 1 opening | 12 | 78 | 15 | 9-1/4 | 69 | 14 | 2PFW5 | 2PGC1 | 63 | 2PGF6 | 2PGK2 | 63 |
| 3 wide, 3 openings | 36 | 78 | 15 | 9-1/4 | 69 | 14 | 2PFW6 | 2PGC2 | 174 | 2PGF7 | 2PGK3 | 174 |
| 1 wide, 1 opening | 12 | 78 | 18 | 9-1/4 | 69 | 17 | 2PFW7 | 2PGC3 | 66 | 2PGF8 | 2PGK4 | 66 |
| 3 wide, 3 openings | 36 | 78 | 18 | 9-1/4 | 69 | 17 | 2PFW8 | 2PGC4 | 180 | 2PGF9 | 2PGK5 | 180 |
| 1 wide, 1 opening | 15 | 78 | 15 | 12-1/4 | 69 | 14 | 2PFW9 | 2PGC5 | 69 | 2PGG1 | 2PGK6 | 69 |
| 3 wide, 3 openings | 45 | 78 | 15 | 12-1/4 | 69 | 14 | 2PFX1 | 2PGC6 | 191 | 2PGG2 | 2PGK7 | 191 |
| 1 wide, 1 opening | 15 | 78 | 18 | 12-1/4 | 69 | 17 | 2PFX2 | 2PGC7 | 73 | 2PGG3 | 2PGK8 | 73 |
| 3 wide, 3 openings | 45 | 78 | 18 | 12-1/4 | 69 | 17 | 2PFX3 | 2PGC8 | 201 | 2PGG4 | 2PGK9 | 201 |
| 1 wide, 1 opening | 18 | 78 | 18 | 15-1/4 | 69 | 17 | 2PFX4 | 2PGC9 | 79 | 2PGG5 | 2PGL1 | 79 |
| 3 wide, 3 openings | 54 | 78 | 18 | 15-1/4 | 69 | 17 | 2PFX5 | 2PGD1 | 219 | 2PGG6 | 2PGL2 | 219 |
| 1 wide, 1 opening | 18 | 78 | 21 | 15-1/4 | 69 | 20 | 2PFX6 | 2PGD2 | 84 | 2PGG7 | 2PGL3 | 84 |
| 3 wide, 3 openings | 54 | 78 | 21 | 15-1/4 | 69 | 20 | 2PFX7 | 2PGD3 | 230 | 2PGG8 | 2PGL4 | 230 |
| DOUBLE TIER WITH LEGS | | | | | | | | | | | | |
| 1 wide, 2 openings | 12 | 78 | 12 | 9-1/4 | 34 | 11 | 2PFX8 | 2PGD4 | 63 | 2PGG9 | 2PGL5 | 60 |
| 3 wide, 6 openings | 36 | 78 | 12 | 9-1/4 | 34 | 11 | 2PFX9 | 2PGD5 | 180 | 2PGH1 | 2PGL6 | 180 |
| 1 wide, 2 openings | 12 | 78 | 15 | 9-1/4 | 34 | 14 | 2PFY1 | 2PGD6 | 67 | 2PGH2 | 2PGL7 | 67 |
| 3 wide, 6 openings | 36 | 78 | 15 | 9-1/4 | 34 | 14 | 2PFY2 | 2PGD7 | 186 | 2PGH3 | 2PGL8 | 186 |
| 1 wide, 2 openings | 12 | 78 | 18 | 9-1/4 | 34 | 17 | 2PFY3 | 2PGD8 | 70 | 2PGH4 | 2PGL9 | 70 |
| 3 wide, 6 openings | 36 | 78 | 18 | 9-1/4 | 34 | 17 | 2PFY4 | 2PGD9 | 192 | 2PGH5 | 2PGN1 | 192 |
| 1 wide, 2 openings | 15 | 78 | 15 | 12-1/4 | 34 | 14 | 2PFY5 | 2PGE1 | 73 | 2PGH6 | 2PGN2 | 73 |
| 3 wide, 6 openings | 45 | 78 | 15 | 12-1/4 | 34 | 14 | 2PFY6 | 2PGE2 | 203 | 2PGH7 | 2PGN3 | 203 |
| 1 wide, 2 openings | 15 | 78 | 18 | 12-1/4 | 34 | 17 | 2PFY7 | 2PGE3 | 78 | 2PGH8 | 2PGN4 | 78 |
| 3 wide, 6 openings | 45 | 78 | 18 | 12-1/4 | 34 | 17 | 2PFY8 | 2PGE4 | 216 | 2PGH9 | 2PGN5 | 216 |
| 1 wide, 2 openings | 18 | 78 | 18 | 15-1/4 | 34 | 17 | 2PFY9 | 2PGE5 | 86 | 2PGJ1 | 2PGN6 | 86 |
| 3 wide, 6 openings | 54 | 78 | 18 | 15-1/4 | 34 | 17 | 2PFZ1 | 2PGE6 | 240 | 2PGJ2 | 2PGN7 | 240 |
| TRIPLE TIER WITH LEGS | | | | | | | | | | | | |
| 1 wide, 3 openings | 12 | 78 | 12 | 9-1/4 | 22-1/4 | 11 | 2PFZ2 | 2PGE7 | 61 | 2PGJ3 | 2PGN8 | 61 |
| 3 wide, 9 openings | 36 | 78 | 12 | 9-1/4 | 22-1/4 | 11 | 2PFZ3 | 2PGE8 | 171 | 2PGJ4 | 2PGN9 | 171 |
| 1 wide, 3 openings | 12 | 78 | 15 | 9-1/4 | 22-1/4 | 14 | 2PFZ4 | 2PGE9 | 65 | 2PGJ5 | 2PGP1 | 65 |
| 3 wide, 9 openings | 36 | 78 | 15 | 9-1/4 | 22-1/4 | 14 | 2PFZ5 | 2PGF1 | 180 | 2PGJ6 | 2PGP2 | 180 |
| 1 wide, 3 openings | 12 | 78 | 18 | 9-1/4 | 22-1/4 | 17 | 2PFZ6 | 2PGF2 | 69 | 2PGJ7 | 2PGP3 | 69 |
| 3 wide, 9 openings | 36 | 78 | 18 | 9-1/4 | 22-1/4 | 17 | 2PFZ7 | 2PGF3 | 189 | 2PGJ8 | 2PGP4 | 189 |