



Technical data

Voltage	U	120	V
Phase		1	~
Frequency		60	Hz
Speed		1655	RPM
Power consumption	P _e	300	W
Nominal current	I	2.9	A
Maximum current	I	3.7	A
Capacitor		25/250	µF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class		IP55	
Weight		24.7	Lbs.



Please note: Picture may deviate from original product

Fan details

Impeller blades	6
Impeller type	3
Impeller system	C
Impeller material	PP

Approval(s)




Control options

Triac controller	Yes
Transformer	Yes
Frequency drive	No
* All control options including single phase control frequency are available. Please contact Vostermans Ventilation Sales for more information	




Characteristics

0.00 in. wg	3750 CFM
0.20 in. wg	3250 CFM
Data according ErP (Energy related Products)-directives (EU Commission Regulation 327/2011).	

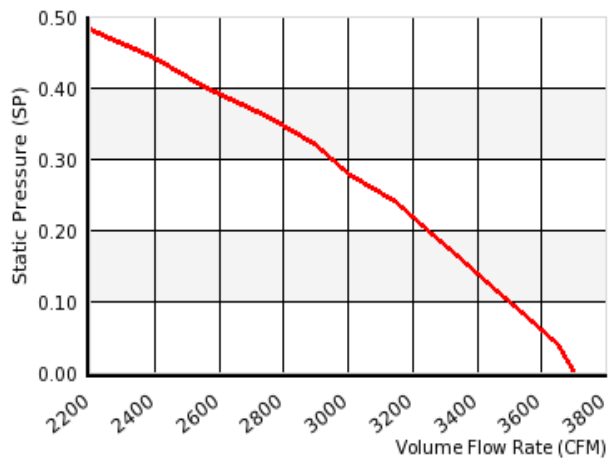


Wiring diagram

AA01 - CCW

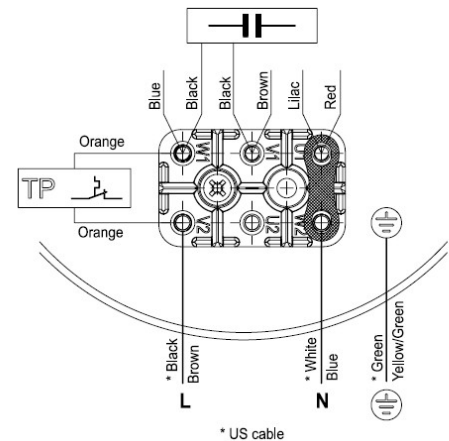

Dimensions

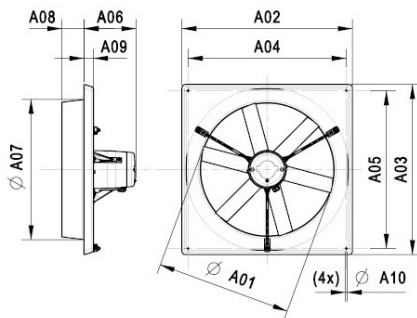

A01	18.1 inch
A02	23.3 inch
A03	23.3 inch
A04	21.5 inch
A05	21.5 inch
A06	9.7 inch
A07	19.3 inch
A08	3.3 inch
A09	1.4 inch
A10	0.3 inch