


Standard features

- Waterproof
- Impact resistant
- Conditional lifetime guarantee
- Crushproof
- Dustproof
- Powerclaw™ latching system
- Soft grip foldable handle
- Lightweight NK-7™ resin
- Padlockable
- 100% stainless steel hardware
- High performance gasket
- Automatic pressure release valve
- Molded-in bezel system
- Integrated lid stay
- Stackable
- Meets airline carry-on regulations

Case specifications

Exterior dimensions	L16.7" x W13.4" x H6.8" L424mm x W340mm x H173mm
Interior dimensions	L15.0" x W10.5" x H6.2" L381mm x W267mm x H157mm
Weight (empty)	5.1 lbs 2.3 kg
Lid depth	2.1" 53mm
Base depth	4.1" 104mm
Material	lightweight NK-7™ resin
Max buoyancy	40 lbs 18.1 kg
Temperature range	Min -20°F (-29°C) Max 140°F (60°C)
Airline carry-on	yes
Watertight	yes
Warranty	conditional lifetime guarantee

Available options

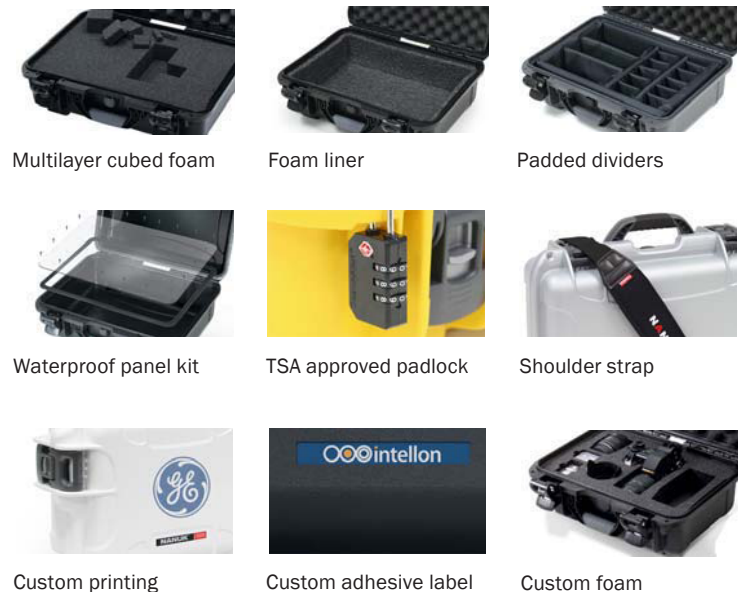

Certifications

ATA 300	Impact test
ASTM D4169	Falling rain - Vibration - Drop tests
MIL-STD-810F	Immersion test
IP 67	Ingress protection tests (dust & immersion)

Packaging specifications

Quantity per pack	1
Pack dimensions	L16.8" x W13.3" x H6.5" L425mm x W336mm x H165mm
Pack weight (no foam)	6.6 lbs 3.0 kg

Available colors



Masterpack specifications

Items per masterpack	4
Masterpack dimensions	L28.4" x W18.9" x H13.8" L720mm x W480mm x H350mm
Masterpack weight	28.5 lbs 12.9 kg