

Nashua® 2280

TAPE PRODUCTS Multi-Purpose Duct Tape

**9 mil Polyethylene-Coated Cloth
Natural Rubber-Based Adhesive**

Available Colors: Silver, Black, Red, White, Blue, Green, Yellow, Brown, Olive Drab, Tan, Burgundy

Standard Sizes: 48mm x 55M, 72mm x 55M


Nashua 2280 is a high performance 9 mil duct tape featuring a smooth, tough, conformable backing that tears smoothly and without difficulty. Its' high tack natural rubber adhesive bonds well to most surfaces making it suitable for a wide range of applications including:

- Maintenance and general repair
- Color coding
- Abatement & contractor uses
- Sealing & hanging PE sheeting
- Joint sealing & pipe wrapping
- Bundling, patching & mending
- Heavy-duty box sealing
- More...



Physical Properties

	Standard UOM	Metric UOM
Total Thickness	9 mils	228.6 mic
Adhesion to Steel	50 oz/in	5.47 N/cm
Tensile Strength	24 lb/in	42.03 N/cm
Operating Temperature	40-200°F	4-93°C
VOC Content	<1 g/L	

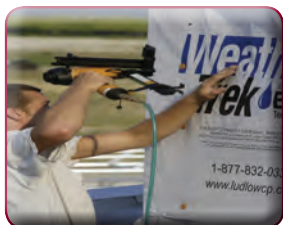

Visit our website
to learn more!



For more information:
25 Forge Parkway
Franklin, MA 02038
Phone 508.918.1600 • Fax 508.918.1901
Toll Free: 1.800.343.7875

tapes.berryplastics.com

BERRY
PLASTICS
CORPORATION
AND SUBSIDIARIES
LEADERSHIP BY DESIGN