

PSP

Plug-In DC Filtered Regulated Power Supply

Medium Capacity Plug-In Power Supply

The PSP Plug-in DC Power Supplies are available in 12 volts at 3 Amp max. capacity (model PSP-12-3) and 24 volts at 1.5 Amp max. capacity (model PSP-24-1.5). 6 ft. output cable is included. Input voltage 100VAC to 240VAC. PSPs are ideal for powering a wide range of DC devices where power is available via an outlet.



PRODUCT FEATURES


- 36 watts continuous output
- 6 ft. [1.8m] output cable included
- Folding, two-prong AC connector
- UL Listed
- MagnaCare Lifetime Replacement No Fault Warranty

MODELS

PART # | Description

PSP-12-3 | Power Supply Plug-In - Switching, Regulated, 12VDC, 3A

PSP-24-1.5 | Power Supply Plug-In - Switching, Regulated, 24VDC, 1.5 A

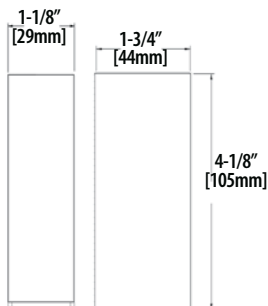

PSP

Plug-In DC Power Supply

Small Plug-In Power Supply

PSP plug-in DC power supplies are available in 12 volts at 700mA max. capacity (model PSP-12) and 24 volts at 350mA capacity (model PSP-24). PSPs are ideal for powering a wide range of DC devices. Accepts 120-240 VAC input.



PRODUCT FEATURES


- Internal thermal fuse
- 12 ft. [3.6m] output cable included
- UL Listed
- 120-240 VAC input
- MagnaCare Lifetime Replacement No Fault Warranty

MODELS

PART # | Description

PSP-12 | Power Supply Plug-In - 12VDC, 700mA

PSP-24 | Power Supply Plug-In - 24VDC, 350mA

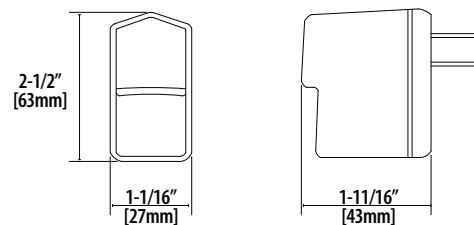

SECURITRON
ASSA ABLOY