

**Product Data**

- Material:** Braided flexible graphite Style 5000
- Construction:** Interwoven™ braid formed to a triangle cross-section
- Temperature Limit:** 1200°F (650°C) steam  
6000°F (3300°C) nonoxidizing atmosphere
- pH Range:** 0 – 14 (all strong oxidizers)
- Pressure Limit:** 900 psi (62 bar)



RINGS




BULK

**Service**

For use in United Conveyor, Dresser, or Allen Sherman Hoff pipe couplers. Especially suited for hot ash handling. Accepts up to 2° pipe misalignment.

STYLE 5000 ASH GASKET

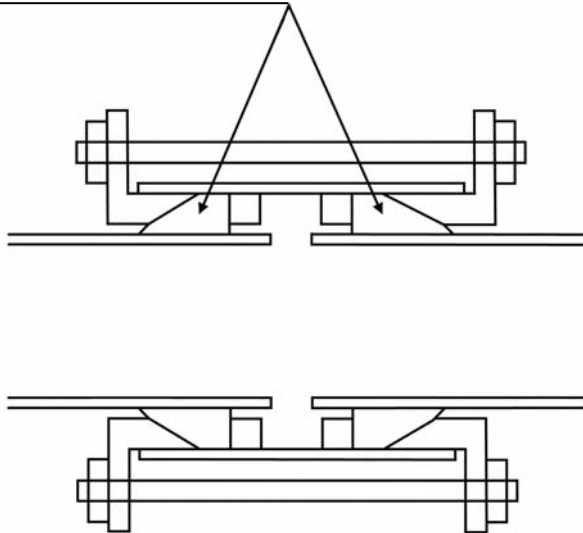

**Distributed by**

A Greene, Tweed Company  
Denton Industrial Park  
25 Engerman Ave., Denton, MD 21629  
Phone: +1.410.479.2244, Fax: +1.410.479.0836  
E-mail: [info@palmettopackings.com](mailto:info@palmettopackings.com)  
Website: [www.palmettopackings.com](http://www.palmettopackings.com)



Product data is based upon our experience and knowledge of typical applications and should be used to determine approximate service compatibility.

All trademarks are property of their respective owners.  
Printed in USA ©2011 Palmetto® Inc.  
01/11-GT DS-US-PI-102