

# Panduit Non-Metallic Surface Raceway - Quick Reference Guide

## Pan-Way® LD Series

 
Spec Sheet: **SRSP21**



Example part: LD3IW6-A  
Colors: IW, EI, IG, WH

- One-piece single channel latching design
- Pre-applied adhesive backed tape


- For routing data and low voltage cabling only (50V or less)
- Available lengths – 6' , 8' , 10'



**LD3 Series**



 **LD5 Series**



**LD10 Series**

## Pan-Way® LDPH Series

 
Spec Sheet: **SRSP30**




Example part: LDPH3IW8-A  
Colors: IW, EI, IG, WH

- Two-piece single channel latching design
- Pre-applied adhesive backed tape with screw mountable option


- For routing cables up to 600V
- Available lengths – 8' , 10'



**LDPH3 Series**

 

**LDPH5 Series**

 

**LDPH10 Series**

## Pan-Way® LDS Series

 
Spec Sheet: **SRSP25**



Example part: LDS3IW10-A  
Colors: IW, EI, IG, WH

- One-piece single channel tamper resistant design
- Bendable in low voltage applications to route over obstructions

- Pre-applied adhesive backed tape
- For routing cables up to 600V
- Available lengths – 10'



**LDS3 Series**



**LDS5 Series**

## Pan-Way® LD2P Series

 
Spec Sheet: **SRSP29**



Example part: LD2P10IW8-A  
Colors: IW, EI, IG, WH

- One-piece dual channel latching design
- Pre-applied adhesive backed tape

- Routes power and data cables together
- Available lengths – 8' , 10'



**LD2P10 Series**

## Pan-Way® T-45 Series

 
Spec Sheet: **SRSP24**



Example part: T45IW8-A  
Colors: IW, EI, WH

- Two-piece single channel with snap-in divider design

- Multi-directional cover hinge allows cable installation from either side
- Available with/without adhesive backed tape
- Available lengths – 8' , 10'



**T45 Series**

IW EI IG WH


Note: Colors shown may differ slightly from actual raceway colors.  
IW=Off white, EI=Electric Ivory, IG=International Gray, WH=White.

**PANDUIT**®

# Panduit Non-Metallic Surface Raceway - Quick Reference Guide


## Pan-Way® T-70 Series

Spec Sheet: **SRSP22**

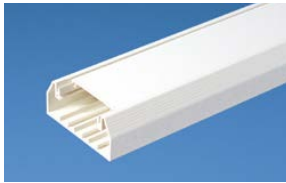

Example part: T70BIW8  
Colors: IW, EI, WH, IG

 - Two-piece single channel with snap-in divider design



2.38" x 1.25"  
A=2.12 in<sup>2</sup>

**T-70 Series**

- Transitions to T-45 and LD profile raceways
- Available lengths – 8', 10'

 
## Pan-Way® Twin-70 Series

Spec Sheet: **SRSP28**



Example part: T702BIW8  
Colors: IW, EI, WH

- Two-piece multi-channel with snap-in divider design



7.23" x 1.77"  
A=4.59 in<sup>2</sup> (Left side)  
A=4.59 in<sup>2</sup> (Right side)

**Twin-70 Series**

- Separate channels allow independent access to power and data cabling
- Available lengths – 8', 10'

 
## Pan-Way® TG-70 Series

Spec Sheet: **SRSP31**



Example part: TG70IW8  
Colors: IW, EI, IG

- Two-piece single channel with snap-in divider design



5.32" x 2.68"  
A=10.85 in<sup>2</sup>

**TG-70 Series**

- Transitions to T-45 and LD profile raceways
- Available lengths – 8', 10'


## Pan-Way® Cove Series

Spec Sheet: **SRSP26**



Example part: WCM35BIW8  
Colors: IW

- Two-piece single channel with snap-in divider design

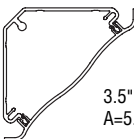

3.5" x 3.5"  
A=5.40 in<sup>2</sup>

**Cove Series**

- Transitions to T-70, T-45 and LD profile raceways
- Used for mounting in between ceiling and wall or between walls
- Available lengths – 8'

## Accessories



**Foam Tape**



**Pan-Way® Faceplates**



**Low Voltage Fittings**



**One-inch Bend Radius Fittings**



**Power Rated Fittings**



**Pan-Way® Junction Boxes**



**Pan-Way® Surface Raceway Cutting Tool**

<sup>1</sup> Office raceway also available in addition to raceway styles listed. For a complete part listing, visit [www.panduit.com](http://www.panduit.com) for our online catalog.

<sup>2</sup> Color availability varies among styles, and certain colors may be limited to specific lengths.