


- 1) ASSEMBLE BASE FRAME USING 1/4" - 20 X 3/4" HEX HEAD BOLTS AND 1/4" WASHERS (18 PLACES)
- 2) ASSEMBLE LEG EXTENDERS USING 1/4" - 20 X 2" HEX HEAD BOLTS, FLAT WASHERS AND ELASTIC LOCK NUTS
- 3) MOUNT DIVIDERS USING 1/4" X 3/8" TRUSS HEAD BOLTS AND WING NUTS
- 4) MOUNT TOP FLUSH TO BACK OF BENCH WITH EQUAL OVERHANG ON BOTH SIDES USING #12 X 2 PHILLIPS PAN HEAD SHEET METAL SCREWS

NOTE: SHELVING AND DIVIDERS ARE OPTIONAL

PRO-LINE
 PACK STATION BASE
 ASSEMBLY INSTRUCTIONS
 DRAWING #A7170


GRAINGER #'S
 4CXW9
 4CXX2
 4CXX4
 4CXX6
 4CXX8
 4CXY1

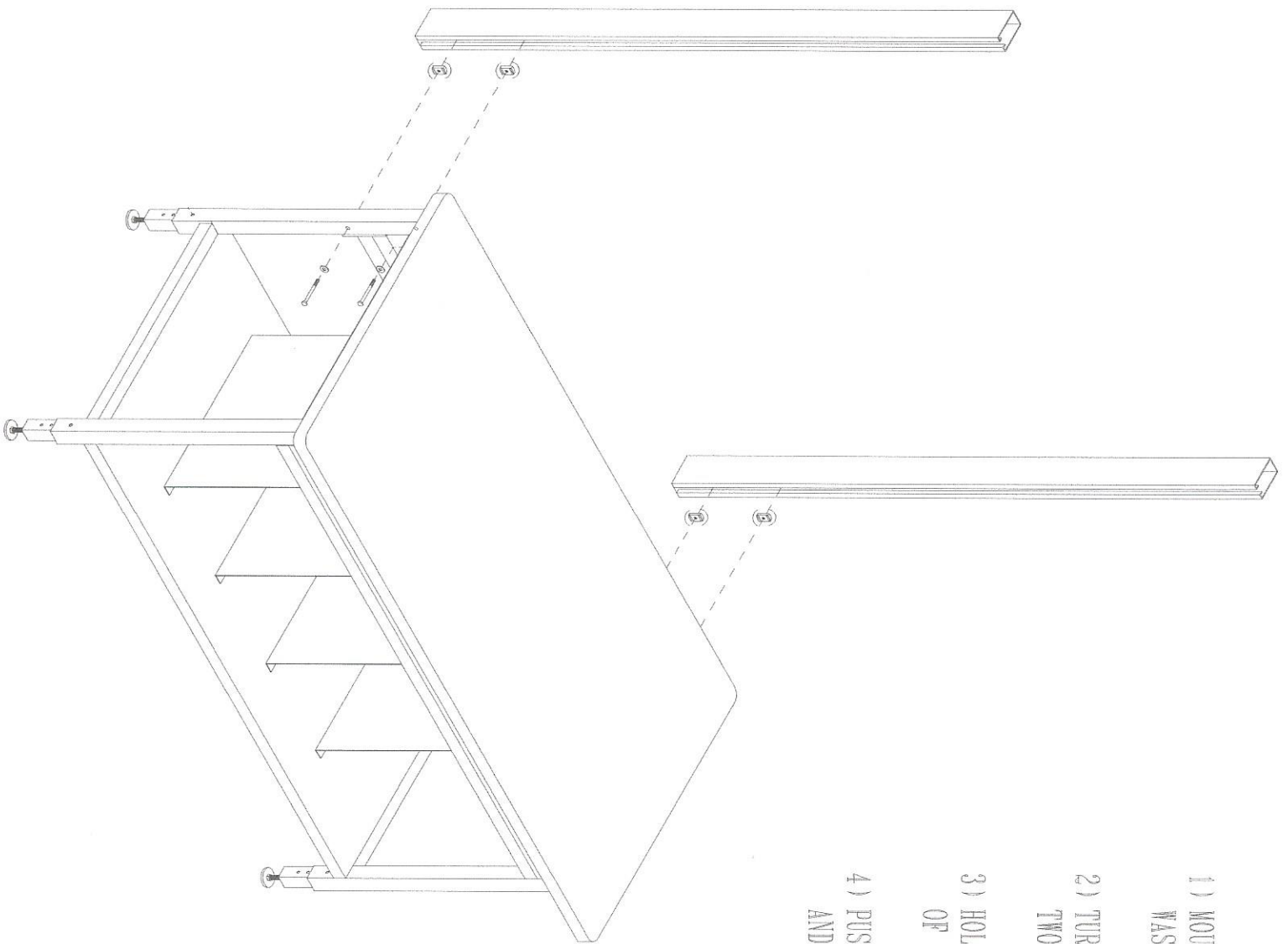

- 1) MOUNT 1/4" X 2 1/2" HEX HEAD BOLTS AND WASHERS THROUGH REAR LEGS AS SHOWN
- 2) TURN 1/4" STRUT NUTS ON APPROXIMATELY TWO (2) THREADS
- 3) HOLD HEAVY DUTY UPRIGHTS AGAINST BACK OF REAR LEGS
- 4) PUSH BOLT ASSEMBLY INTO UPRIGHTS AND TURN CLOCKWISE TO TIGHTEN

- GRAINGER #'S
- 4CXM9
 - 4CXX2
 - 4CXX4
 - 4CXX6
 - 4CXX8
 - 4CXY1

PRO-LINE
 PACK STATION UPRIGHT ASSEMBLY
 INSTRUCTIONS
 DRAWING #47241

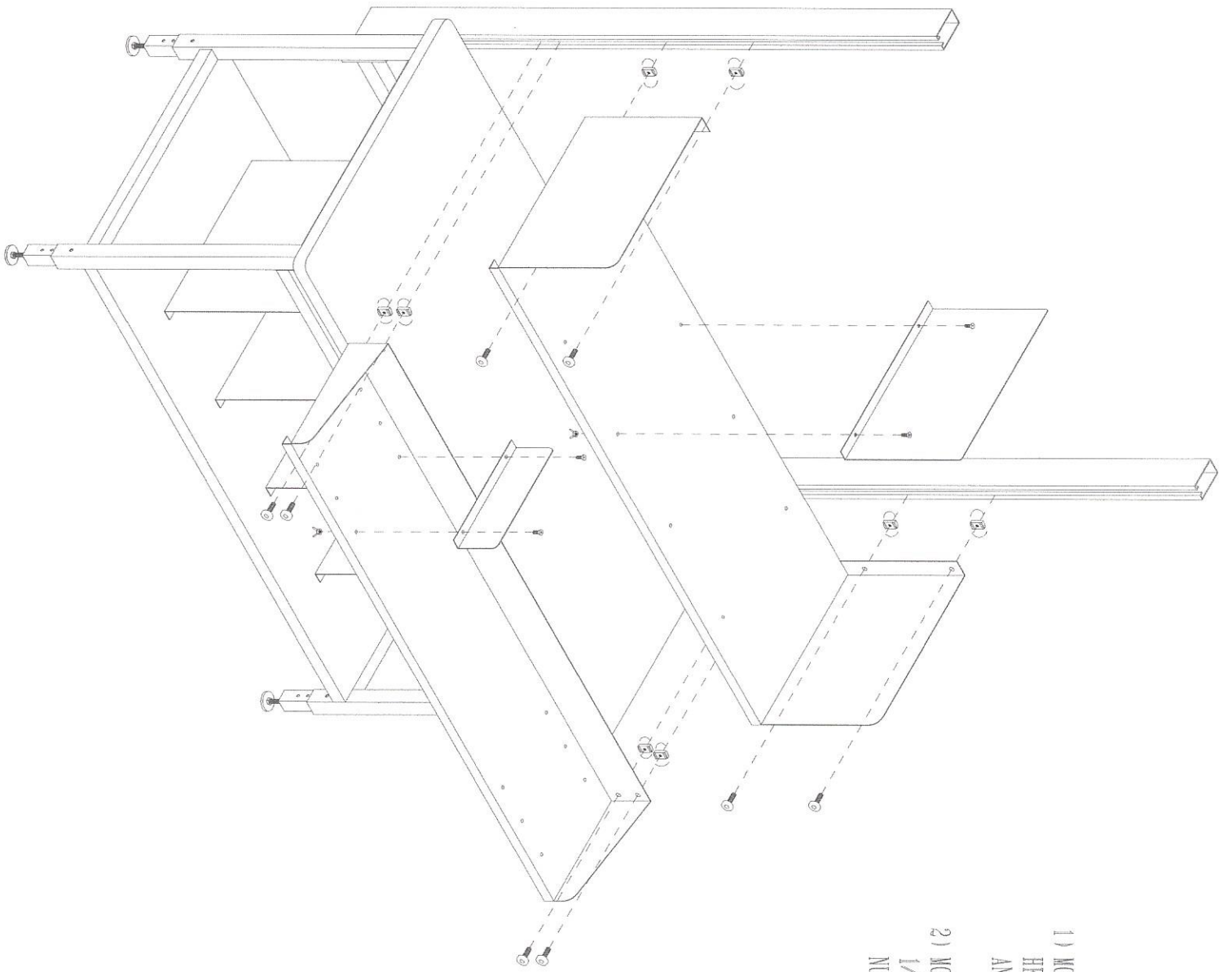


1) MOUNT SHELVES TO UPRIGHTS AT DESIRED HEIGHTS USING 3/8" X 1" ALLEN CAP SCREWS AND 3/8" STRUT NUTS

2) MOUNT DIVIDERS TO THE SHELVES USING 1/4" X 3/8" TRUSS HEAD BOLTS AND WING NUTS

- GRAINGER #'S
 4CXM9
 4CXX2
 4CXX4
 4CXX6
 4CXX8
 4CXV1

PRO-LINE
 PACK STATION TOP SHELF
 ASSEMBLY INSTRUCTIONS
 DRAWING #A7171

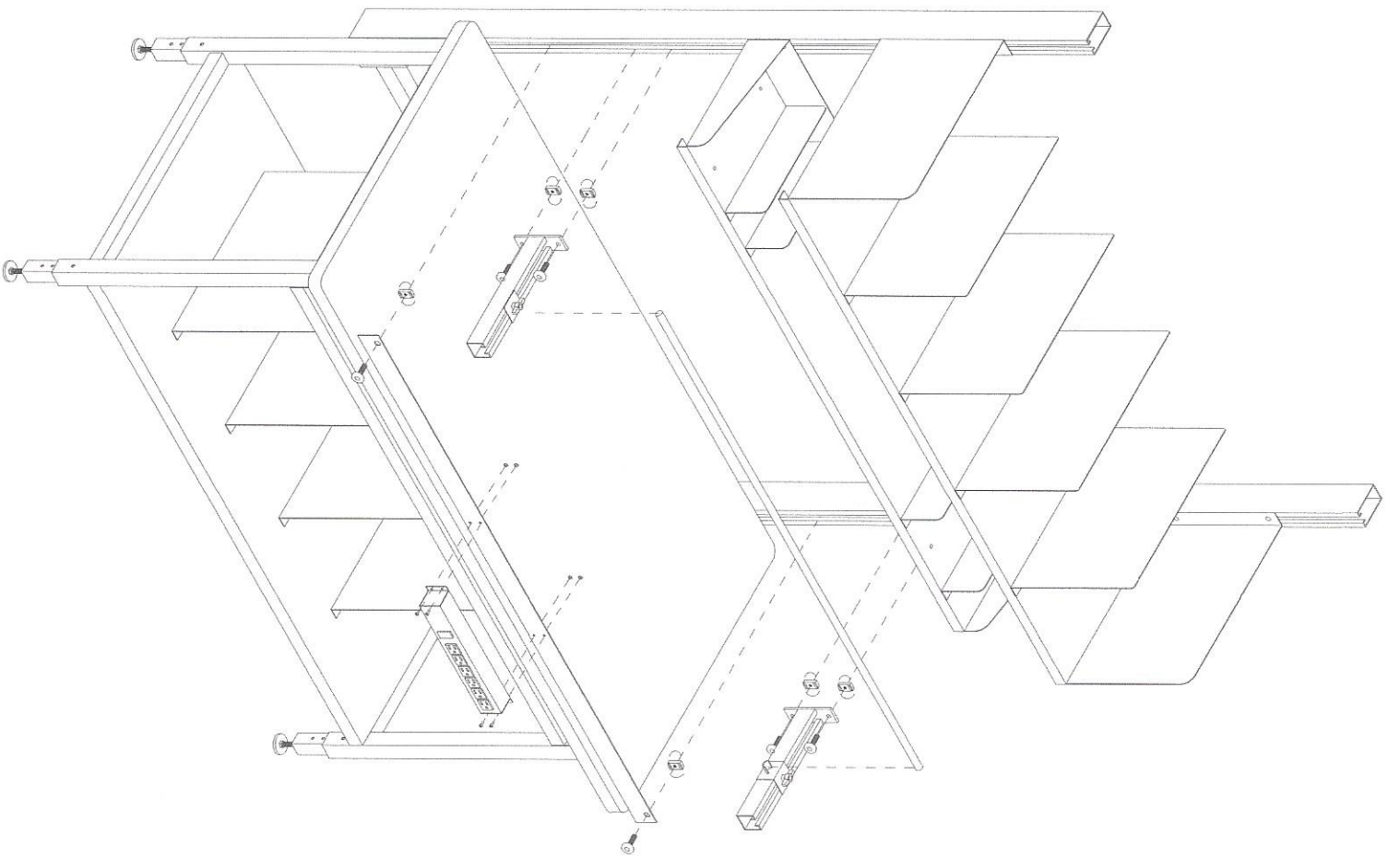


1) MOUNT PAPER SPOOL HOLDER AND ESMR AT DESIRED HEIGHT USING 3/8" X 1" ALLEN CAP SCREWS AND STRUT NUTS

2) SECURE THE ELECTRICAL STRIP TO THE ESMR AS SHOWN USING 6/32" X 3/8" ROUND HEAD MACHINE SCREWS AND 6/32" HEX NUTS.

PRO-LINE
 PACK STATION ESMR AND ES/
 SPOOL HOLDER ASSEMBLY
 INSTRUCTIONS
 DRAWING # A7172

GRAINGER #'S
 4CXX9
 4CXX2
 4CXX4
 4CXX6
 4CXX8
 4CXY1

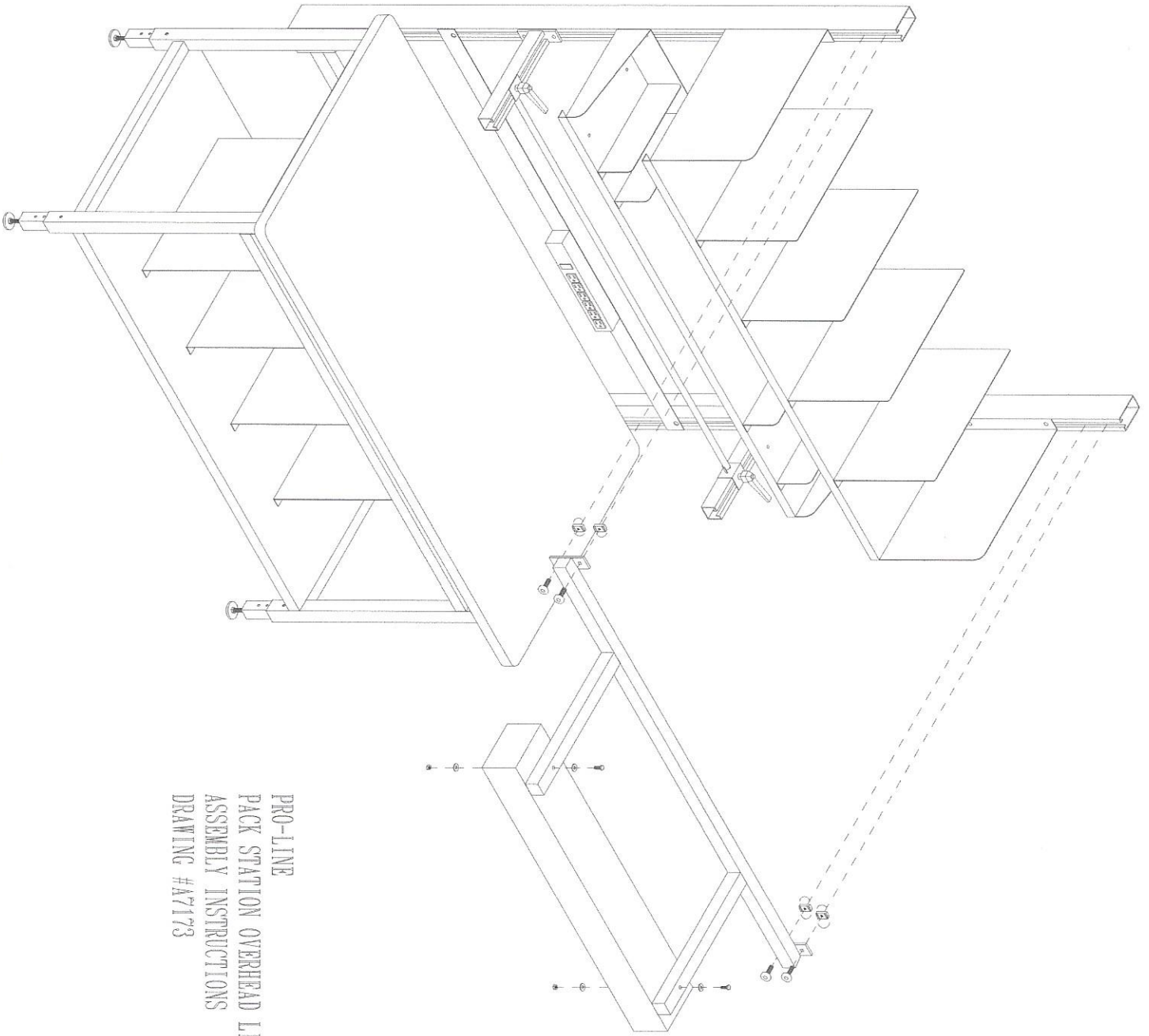

PRO-LINE
 PACK STATION OVERHEAD LIGHT
 ASSEMBLY INSTRUCTIONS
 DRAWING #A7173

1) MOUNT LIGHT FRAME TO UPRIGHTS
 USING 3/8" X 1" ALLEN CAP SCREWS
 AND 3/8" STRUT NUTS

2) MOUNT LIGHT FIXTURE TO LIGHT
 FRAME USING 1/4" - 20 X 2"
 HEX HEAD BOLTS 1/4" FLAT
 WASHERS AND 1/4" KEPNUTS

RECOMMENDED BULBS

36" FIXTURES F30 T8
 F25 T8

GRANGER #'S

4CXM9
 4CXX2
 4CXX4
 4CXX6
 4CXX8
 4CXY1