



5 SERIES

Kingpinless Pressed Steel

Ideally suited for moving moderate to heavy loads over flat surfaces, Revvo TS5 Series casters are available in three wheel sizes (6", 6-1/4" & 8") with load capacities ranging from 660 to 2,200 lbs. Swivel models (TS5/BS5) are fitted with head seals to prevent the ingress of dirt and dust into the swivel head. Fixed models (TF5) are fitted with oblong top plates. Please consult factory for load capacities of bolt hole models.


Options & Accessories

See Page 8 for complete specifications, availability and ordering information


Item	Availability	Order Ref.
Threadguards	Swivel & Fixed*	T
Head Seals	Swivel (standard)	S
Wheel Lock	Swivel	W
Foot Brake	Swivel (6" & 8")	H
Swivel & Wheel Lock	Swivel (6" & 8")	L
Round Steel Plugs	Bolt Hole	RP

* Threadguards are available for all 5 Series casters except models with Green Rubber wheels

Note: Head Seals are fitted standard on all top plate and bolt hole 5 Series swivel casters.

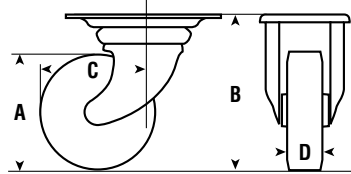

Standard Top Plate

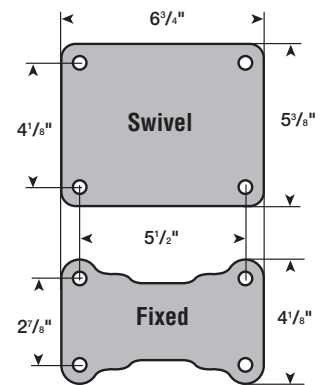

TS5/TF5 top plates have fixing holes to suit 3/8" diameter bolts.

BS5 bolt hole frames have a mounting center hole of 3/4".

A = Wheel Diameter B = Overall Height C = Swivel Radius D = Tread Width

5 SERIES				TS5/TF5*	Top Plate				Bolt Hole
A	B	C	D	Load Capacity	Bearing	Wheel	Swivel Part #	Fixed Part #	Swivel Part #
6"	8"	5-1/16"	1-1/2"	1100	Roller	Nylon	TS5 150 NY15	TF5 150 NY15	BS5 150 NY15
6"	8"	5-1/16"	1-1/2"	1760	Precision Ball	Nylon	TS5 150 NY2H	TF5 150 NY2H	BS5 150 NY2H
6"	8"	5-1/16"	2"	1200	Roller	Phenolic	TS5 150 RP1G	TF5 150 RP1G	BS5 150 RP1G
6"	8"	5-1/16"	1-3/4"	800	Roller	Rubber Tire	TS5 150 RU15	TF5 150 RU15	BS5 150 RU15
6"	8"	5-1/16"	1-3/4"	800	Precision Ball	Rubber Tire	TS5 150 RU2H	TF5 150 RU2H	BS5 150 RU2H
6"	8"	5-1/16"	1-1/2"	1600	Roller	Revvothane	TS5 150 PT15	TF5 150 PT15	BS5 150 PT15
6"	8"	5-1/16"	2"	750	Roller	Polypropylene	TS5 150 PL1G	TF5 150 PL1G	BS5 150 PL1G
6"	8"	5-1/16"	1-3/4"	2000	Roller	Cast Iron	TS5 150 CI15	TF5 150 CI15	BS5 150 CI15
6"	8"	5-1/16"	1-1/2"	1250	Roller	Polyurethane	TS5 150 PU1G	TF5 150 PU1G	BS5 150 PU1G
6 1/4"	8-3/16"	5-1/4"	1-5/8"	660	Precision Ball	Green Rubber	TS5 160 GR2H	TF5 160 GR2H	BS5 160 GR2H
8"	9-3/4"	6-1/16"	1-1/2"	1100	Roller	Nylon	TS5 200 NY15	TF5 200 NY15	BS5 200 NY15
8"	9-3/4"	6-1/16"	1-1/2"	2200	Precision Ball	Nylon	TS5 200 NY2H	TF5 200 NY2H	BS5 200 NY2H
8"	9-3/4"	6-1/16"	1-5/8"	880	Precision Ball	Green Rubber	TS5 200 GR2H	TF5 200 GR2H	BS5 200 GR2H
8"	9-3/4"	6-1/16"	2"	1400	Roller	Phenolic	TS5 200 RP1G	TF5 200 RP1G	BS5 200 RP1G
8"	9-3/4"	6-1/16"	2"	1175	Roller	Rubber Tire	TS5 200 RU15	TF5 200 RU15	BS5 200 RU15
8"	9-3/4"	6-1/16"	2"	1175	Precision Ball	Rubber Tire	TS5 200 RU2H	TF5 200 RU2H	BS5 200 RU2H
8"	9-3/4"	6-1/16"	1-3/4"	2200	Roller	Revvothane	TS5 200 PT15	TF5 200 PT15	BS5 200 PT15
8"	9-3/4"	6-1/16"	2"	1000	Roller	Polypropylene	TS5 200 PL1G	TF5 200 PL1G	BS5 200 PL1G
8"	9-3/4"	6-1/16"	1-3/4"	2200	Roller	Cast Iron	TS5 200 CI15	TF5 200 CI15	BS5 200 CI15
8"	9-3/4"	6-1/16"	2"	1925	Roller	Polyurethane	TS5 200 PU1G	TF5 200 PU1G	BS5 200 PU1G

* Load capacities are shown for top plate models (TS5/TF5) only. Please consult factory for load capacities of individual bolt hole casters.



OPTIONS & ACCESSORIES

1 Series 2 Series 3 Series 4 Series 5 Series

Threadguards (T)

- For swivel casters only
- Prevents string, thread, etc. from binding the wheel
- To order, add suffix **T** to Swivel Part #

Available for:

- 1 Series - TS1/BS1
- 2 Series - TS2/BS2
- 3 Series - TS3/BS3
- 4 Series - TS4/BS4
- 5 Series - TS5/BS5





Expanding Plugs (R/S)

Supplied in three Round (nylon) sizes:

Expands from	Reference #
19/32" to 23/32"	R15
23/32" to 27/32"	R18
27/32" to 31/32"	R21

Supplied in two Square (steel) sizes:

Expands from	Reference #
19/32" to 21/32"	S15
27/32" to 15/16"	S21

  

To order round or square plugs, add Reference # to Swivel Part #

Available for:


- 1 Series - BS1
- 2 Series - BS2

Head Seals (S)

- For swivel casters only
- Prevents the ingress of dirt and dust to swivel head
- To order, add suffix **S** to Swivel Part #

Available for:

- 3 Series - TS3/BS3
- 4 Series - TS4/BS4
- 5 Series - TS5/BS5

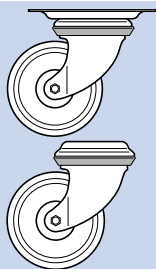

Sprung Plugs (SA)

For mobile steps - fitted with a 5-1/4" stepped plug fitted into a 1" O.D. outer sleeve that compresses on loading


Supplied in two spring weights:

Spring weight	Reference #
33 lbs.	SA1
66 lbs.	SA2

To order, add Reference # to Swivel Part #

Available for:

- 1 Series - BS1
- 2 Series - BS2

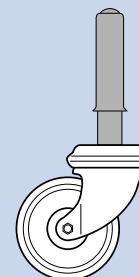


Foot Brake (B)

- For light-duty swivel casters only
- Foot-operated pedal locks wheel
- To order, add suffix **B** to Swivel Part #

Available for:

- 1 Series - TS1/BS1 (2" & 2-1/2" only)
- 2 Series - TS2/BS2
- 3 Series - TS3/BS3

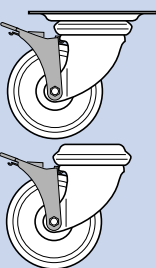


Round Steel Plugs (RP)

Supplied in two sizes:

Plug Diameter	Reference #
1"	RP3
1-1/4"	RP5

Available for:

- 3 Series - BS3
- 4 Series - BS4

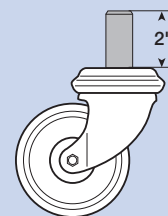


Foot Brake (H)

- For medium-duty swivel casters only
- Foot-operated pedal locks wheel
- To order, add suffix **H** to Swivel Part #

Available for:

- 4 Series - TS4/BS4 (4" & 5" only)
- 5 Series - TS5/BS5 (6" & 8" only)

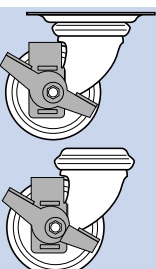

Round Steel Plugs (RP)


Supplied in two sizes:

Plug Diameter	Reference #
1-3/8"	RP7
1-1/2"	RP8

To order, add Reference # to Swivel Part #

Available for:

- 5 Series - BS5

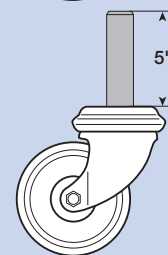

Wheel Lock (W)

- For swivel casters only
- A simple hand-operated parking lock
- To order, add suffix **W** to Swivel Part #

Available for:

- 4 Series - TS4/BS4
- 5 Series - TS5/BS5 (6" & 8" only)



Expanding Steel Plugs (EP)


Supplied in four sizes:

Expands from	Reference #
23/32" to 25/32"	EP1
27/32" to 15/16"	EP2
31/32" to 1-1/32"	EP3
1-3/32" to 1-5/32"	EP4

To order, add Reference # to Part #

Available for:

- 3 Series - BS3
- 4 Series - BS4

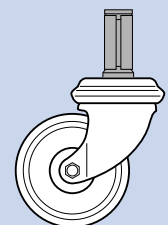

Swivel & Wheel Lock (L)

- For swivel casters only
- The foot pedal locks both the wheel and swivel
- To order, add suffix **L** to Swivel Part #

Available for:

- 4 Series - TS4/BS4 (4" & 5" only)
- 5 Series - TS5/BS5 (6" & 8" only)

