




# SINGLE POINT


ALL-WELDED VENTILATED

**FEATURES:**

**BODY CONSTRUCTION:** All-welded, fully-assembled  
**BODY STYLES:** Single and double tier  
**CUSTOM FEATURES:** 16 gauge continuous top for added rigidity, 11 gauge MIG welded latch, continuous door strike at hinge and latch side  
**DOOR:** 14 gauge door is diamond perforated for added visibility and ventilation and includes a welded-in full height door stiffener  
**HINGES:** Piano hinge type  
**HANDLE:** Deep-drawn seamless stainless steel recessed handle with single-point thru-the-handle maintenance-free quiet latching system  
**SHELVES:** Hat shelf for single tier lockers

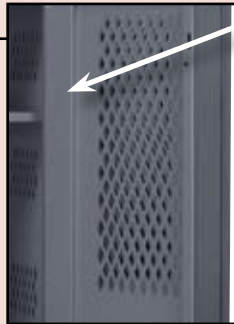

Lockers include a 3" wide 18 gauge full height door stiffener spot welded to the inner door face and MIG welded to the hinge side as well as to the top and bottom door flanges providing a rigid torque-free door.

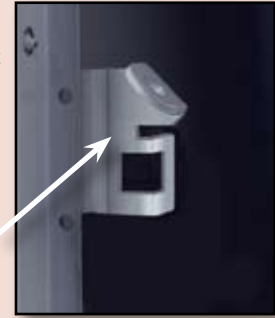

Single-point maintenance-free quiet latching system with recessed handle


Single Tier,  
1 wide,  
1 opening



Single Tier,  
3 wide,  
3 openings



Double Tier,  
3 wide,  
6 openings

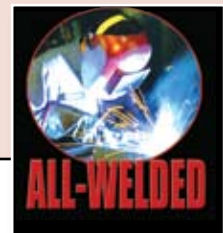

Locker Type	Overall Dimensions (In.)			Opening Dimensions (In.)			Weight	Fully-Assembled Hallowell Gray
	W	H	D	W	H	D		
<b>SINGLE TIER</b>								
1-wide 1 Opening	12	72	12	9-1/4	69	11	84	2PGY2
3-wide 3 Openings	12	72	12	9-1/4	69	11	222	2PGY3
1-wide 1 Opening	12	72	18	9-1/4	69	17	90	2PGY4
3-wide 3 Openings	12	72	18	9-1/4	69	17	225	2PGY5
1-wide 1 Opening	18	72	18	15-1/4	69	17	116	2PGY6
3-wide 3 Openings	18	72	18	15-1/4	69	17	303	2PGY7
<b>DOUBLE TIER</b>								
1-wide 2 Opening	12	72	12	9-1/4	34	11	96	2PGY8
3-wide 6 Openings	12	72	12	9-1/4	34	11	228	2PGY9
1-wide 2 Opening	12	72	18	9-1/4	34	17	96	2PGZ1
3-wide 6 Openings	12	72	18	9-1/4	34	17	243	2PGZ2
1-wide 2 Opening	18	72	18	15-1/4	34	17	122	2PGZ3
3-wide 6 Openings	18	72	18	15-1/4	34	17	321	2PGZ4

