

# Combination Power Series AIR COMPRESSOR/GENERATOR



## 8-GALLON, SINGLE OR TWO-STAGE MODELS

The combination air compressor/generator provides the convenience of two machines in one. The 8-gallon receiver gasoline models feature a single or two-stage oil splash-lubricated cast-iron compressor pump, 120V 1600 or 3500-watt rated generator, and a 6.5 or 13 HP Honda engine with recoil start or electric start (battery and cables not included). Includes 1/4-inch outlet with quick coupler socket

SKU NO.	HP	CFM @ 90 PSI	RATED WATTS ON/OFF LOAD	AIR TANK	STARTER TYPE	OUTLET	RECEPTACLE	DIMENSIONS (IN.)			UNIT WT (LBS.)
								L	W	H	
<b>8-GALLON, SINGLE STAGE AIR COMPRESSOR/GENERATOR COMBINATION</b>											
4NB86	6.5	12.4	1600/600	8 gallon portable	Recoil	1/4"	(1) 120V, 15A duplex	44.5	26	27.5	207
<b>8-GALLON, TWO STAGE AIR COMPRESSOR/GENERATOR COMBINATION</b>											
13N456	13	16.4	3500/2300	8 gallon portable	Recoil	1/4"	(2) 120V, 15- amp duplex, (1) 240V, 20A	52	28	34	375
13N457	13	16.4	3500/2300	8 gallon portable	Electric	1/4"	(2) 120V, 15- amp duplex, (1) 240V, 20A	52	28	34	375
4NB87	13	16.4	3500/2300	8 gallon stationary	Recoil	1/4"	(2) 120V, 15- amp duplex, (1) 240V, 20A	44	22	34	365
6EWK4	13	16.4	3500/2300	8 gallon stationary	Electric	1/4"	(2) 120V, 15- amp duplex, (1) 240V, 20A	44	22	34	365



4NB86




6EWK4

## 30-GALLON, TWO-STAGE MODELS

The combination air compressor/generator provides the convenience of two machines in one. The 30-gallon ASME coded receiver gasoline models feature a two-stage oil splash-lubricated cast-iron compressor pump, 120V 3500-watt rated generator, and a 13 HP Honda engine with recoil start or electric start (battery and cables not included). Includes 1/4-inch outlet with quick coupler socket. 6EWK6 has an optional battery tray available.

SKU NO.	HP	CFM @ 90 PSI	RATED WATTS ON/OFF LOAD	AIR TANK	STARTER TYPE	OUTLET	RECEPTACLE	DIMENSIONS (IN.)			UNIT WT (LBS.)
								L	W	H	
<b>30-GALLON, TWO STAGE AIR COMPRESSOR/GENERATOR COMBINATION</b>											
6EWK5	13	16.4	3500/2300	30 gallon stationary	Recoil	1/4"	(2) 120V, 15- amp duplex, (1) 240V, 20A	40	24.5	45	450
6EWK6	13	16.4	3500/2300	30 gallon stationary	Electric	1/4"	(2) 120V, 15- amp duplex, (1) 240V, 20A	40	24.5	45	450

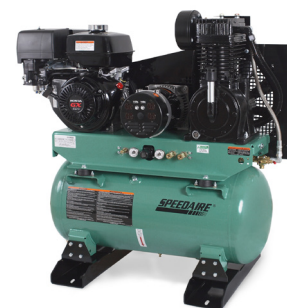

6EWK5



The Grainger Choice badge signals a broad selection of products that deliver quality and value, brought to you by Grainger.

Call or visit your local branch or go to [grainger.com/speedaire](http://grainger.com/speedaire) for complete product line information