

SAVE-T[®]

FLEXIBLE PVC STRIP, SHEET & PANEL

**STANDARD, USDA LOW TEMP,
EXTRA LOW TEMP,
ANTI-STATIC,
OPAQUES, TINTS,
WELD SCREENS
and more**

- .030" to .500"
Material Available
- Flat & Offset Double Ribbed
- UV Stabilized




Managing Environments™

ABOUT TMI, LLC

TMI, LLC is a leading US manufacturer of flexible and rigid PVC strip, sheet, panel, and film. For over fifteen years, TMI has been a trusted name in PVC extrusion. TMI has the most extensive extrusion capabilities in the industry, with multiple extrusion lines and over 150 stocked compounds. Extruded PVC is available in thicknesses from .030" up to .500", and in widths from 4" up to 60". Additional extrusion capabilities include EVA, TPR, TPE, and other polymers.

THE TMI, LLC ADVANTAGE

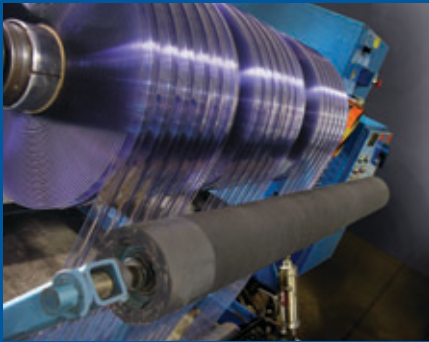

TMI, LLC IN ACTION



Extruded PVC products are made in the United States at our Cuyahoga Falls, OH plant. Every compound and resin used in the extrusion process is made in the US. TMI sets industry standards in quality and is known throughout the industry for its unmatched clarity. TMI can also develop special compounds for custom applications. With low minimum requirements and the fastest lead times, TMI offers the most diversified line of PVC extrusions in the nation.

TMI's flexible PVC does not include any harmful DOP plasticizer, heavy metal or odorous tin additives. Most of our products ship directly from our large inventories within 24 hours. Custom production runs typically ship within two weeks from receipt of the order. TMI carries in excess of 300 different items of PVC Strip, Sheet, Panel and Film.



TMI's flexible PVC material is used to manage energy and environmental control applications, most often seen in flexible PVC strip doors, enclosures, and clean room environments. Some of the most common industries and applications of TMI's flexible and rigid PVC include:

- Loading Docks
- Manufacturing Plants
- Warehouses
- Food Processing
- Modular Enclosures
- Conveyors
- Welding
- Coolers and Freezers
- Clean Room
- Restaurants
- Retail Stores
- Security
- Insect Barriers
- Noise Barriers
- Temperature Barriers
- Signs and Banners
- Tank Lining
- Liquid Dams

**Custom runs for 1,500 lbs.
or more are available**



STANDARD CLEAR PVC STRIP AND SHEET

Standard Clear Flat – Strip (0° to 150° F)

Width x Thickness	Roll Length	Roll Weight	Width x Thickness	Roll Length	Roll Weight
4" x .040"	500 ft.	42 lbs	24" x .080"	60 ft.	60 lbs
4" x .060"	300 ft.	38 lbs	24" x .120"	60 ft.	90 lbs
4" x .060"	400 ft.	50 lbs	24" x .160"	60 ft.	120 lbs
6" x .040"	500 ft.	63 lbs	24" x .240"	60 ft.	180 lbs
6" x .060"	300 ft.	57 lbs	36" x .080"	60 ft.	90 lbs
6" x .060"	400 ft.	75 lbs	36" x .120"	60 ft.	135 lbs
8" x .080"	105 ft.	35 lbs	36" x .160"	60 ft.	180 lbs
8" x .080"	300 ft.	100 lbs	36" x .240"	60 ft.	270 lbs
8" x .120"	105 ft.	153 lbs	48" x .040"	150 ft.	150 lbs
8" x .120"	200 ft.	100 lbs	48" x .060"	60 ft.	90 lbs
12" x .080"	105 ft.	53 lbs	48" x .080"	60 ft.	120 lbs
12" x .080"	300 ft.	150 lbs	48" x .080"	120ft.	240 lbs
12" x .120"	105 ft.	79 lbs	48" x .120"	60 ft.	180 lbs
12" x .120"	150 ft.	113 lbs	48" x .160"	60 ft.	240 lbs
12" x .120"	200 ft.	150 lbs	48" x .240"	60 ft.	360 lbs
12" x .160"	100 ft.	100 lbs	54" x .040"	84 ft.	189 lbs
16" x .080"	200 ft.	134 lbs	54" x .060"	60 ft.	102 lbs
16" x .120"	100 ft.	100 lbs	60" x .080"	60 ft.	150 lbs
16" x .160"	100 ft.	134 lbs	60" x .120"	60 ft.	225 lbs
16" x .160"	150 ft.	200 lbs	60" x .160"	60 ft.	300 lbs



- Exceptional Clarity
- UV Stabilized
- CFM Compliant Material Available
- Recommended for applications above freezing and temperatures as high as 150° F

LOW TEMPERATURE USDA CLEAR PVC STRIP

USDA Low Temperature PVC - Strip (-20° to 140° F)

Width x Thickness	Roll Length	Roll Weight	Width x Thickness	Roll Length	Roll Weight
4" x .060"	300 ft.	38 lbs	24" x .080"	60 Feet	60 lbs
6" x .060"	300 ft.	57 lbs	24" x .120"	60 Feet	90 lbs
6" x .060"	400 ft.	75 lbs	36" x .080"	60 Feet	90 lbs
8" x .080"	300 ft.	100 lbs	36" x .120"	60 Feet	135 lbs
8" x .120"	200 ft.	100 lbs	48" x .080"	60 Feet	120 lbs
12" x .080"	300 ft.	150 lbs	48" x .120"	60 Feet	180 lbs
12" x .120"	200 ft.	150 lbs	48" x .160"	60 Feet	240 lbs
16" x .160"	100 ft.	134 lbs			



USDA Low Temp Reinforced - Strip (-20° to 140° F)

Width x Thickness	Roll Length	Roll Weight
6" x .060"	300 ft.	57 lbs
6" x .060"	400 ft.	75 lbs
8" x .080"	300 ft.	100 lbs
12" x .080"	200 ft.	100 lbs
12" x .120"	200 ft.	150 lbs
16" x .160"	100 ft.	134 lbs

Extra Low Temp PVC - Strip (-40° to 140° F)

Width x Thickness	Roll Length	Roll Weight
8" x .080"	300 ft.	100 lbs
12" x .120"	200 ft.	150 lbs
16" x .160"	100 ft.	134 lbs


OFFSET DOUBLE RIBBED STRIP

Offset Double Ribbed Clear - Strip (0° to 150° F)


Width x Thickness	Roll Length	Roll Weight
8" x .072"	150 ft.	60 lbs
12" x .108"	150 ft.	124 lbs
16" x .144"	100 ft.	141 lbs

USDA Low Temp Ribbed - Strip (-20° to 140° F)

Width x Thickness	Roll Length	Roll Weight
8" x .072"	150 ft.	60 lbs
12" x .108"	150 ft.	124 lbs
16" x .144"	100 ft.	141 lbs

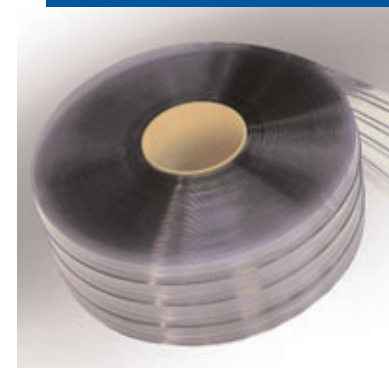

1-800-888-9750

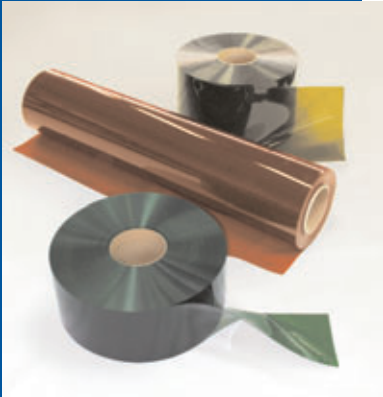

• CFM Compliant Material Available.

WELD SCREEN AND TINTED TRANSPARENT PVC

Aztec Red and Dark Green Strip and Sheet (0° to 150° F)

Width x Thickness	Roll Length	Roll Weight
8" x .080"	300 ft.	100 lbs
12" x .120"	200 ft.	150 lbs
16" x .160"	100 ft.	134 lbs
48" x .040"	150 ft.	150 lbs
48" x .080"	60 ft.	120 lbs
60" x .040"	120 ft.	150 lbs

Amber Strip and Sheet (0° to 150° F)

Width x Thickness	Roll Length	Roll Weight
6" x .040"	500 ft.	63 lbs
8" x .080"	300 ft.	100 lbs
12" x .080"	300 ft.	150 lbs
12" x .120"	200 ft.	150 lbs
16" x .160"	100 ft.	134 lbs
48" x .040"	150 ft.	150 lbs
48" x .080"	60 ft.	120 lbs
48" x .120"	60 ft.	180 lbs
48" x .160"	60 ft.	240 lbs
60" x .040"	120 ft.	150 lbs

- Protects against the effects of UV light emitted during arc welding.
- Eye protection should be worn for direct viewing of welding arcs even through this material.



ANTI-STATIC PVC STRIP AND SHEET (0° to 150° F)

STATIC-SHIELD™

ANTI-STATIC PVC STRIP AND SHEET (0° to 150° F)

Width x Thickness	Roll Length	Roll Weight
8" x .080"	300 ft.	100 lbs
6" x .060"	400 ft.	75 lbs
8" x .060"	400 ft.	100 lbs
8" x .080"	300 ft.	100 lbs
12" x .060"	400 ft.	150 lbs
12" x .120"	200 ft.	150 lbs
36" x .040"	120 ft.	90 lbs
36" x .080"	60 ft.	90 lbs
36" x .080"	120 ft.	180 lbs
36" x .120"	60 ft.	135 lbs

Width x Thickness	Roll Length	Roll Weight
48" x .040"	150 ft.	150 lbs
48" x .060"	60 ft.	90 lbs
48" x .080"	60 ft.	120 lbs
48" x .080"	120 ft.	240 lbs
48" x .120"	60 ft.	180 lbs
54" x .040"	84 ft.	189 lbs
54" x .080"	120 ft.	270 lbs
60" x .080"	120 ft.	360 lbs

- Static-Shield™ offers 52% greater surface resistivity and improved volume resistivity compared to other anti-static flexible PVC products in the market today. Available in strip and sheet form.



OPAQUE AND TINTED PVC (0° to 150° F)

Black Opaque - Strip & Sheet

Width x Thickness	Roll Length	Roll Weight
4" x .060"	300 ft.	50 lbs
8" x .080"	300 ft.	100 lbs
12" x .120"	200 ft.	150 lbs
16" x .160"	100 ft.	134 lbs
48" x .080"	60 ft.	120 lbs
48" x .240"	60 ft.	360 lbs

Charcoal Tint - Strip

Width x Thickness	Roll Length	Roll Weight
8" x .080"	300 ft.	100 lbs
12" x .120"	200 ft.	150 lbs

Ocean Blue Tint - Strip

Width x Thickness	Roll Length	Roll Weight
8" x .080"	300 ft.	100 lbs
12" x .120"	200 ft.	150 lbs

White Opaque - Strip

Width x Thickness	Roll Length	Roll Weight
12" x .120"	75 ft.	57 lbs


Frosty Transparent - Strip

Width x Thickness	Roll Length	Roll Weight
6" x .060"	400 ft.	75 lbs
8" x .060"	400 ft.	100 lbs
8" x .080"	300 ft.	100 lbs
8" x .120"	200 ft.	100 lbs
12" x .060"	400 ft.	150 lbs
12" x .120"	200 ft.	150 lbs

Royal Blue Opaque* - Strip

Width x Thickness	Roll Length	Roll Weight
8" x .080"	300 ft.	100 lbs
12" x .120"	200 ft.	150 lbs

* Special Order

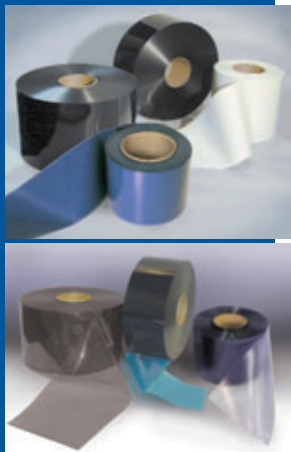

- For applications where light transmission and visibility are to be reduced or eliminated.
- CFM Compliant Material Available.

SAFETY ORANGE

PVC STRIP (0° to 150° F)

Width x Thickness	Roll Length	Roll Weight
4" x .080"	300 ft.	50 lbs
6" x .120"	200 ft.	75 lbs
8" x .080"	300 ft.	100 lbs
8" x .120"	200 ft.	100 lbs
12" x .120"	200 ft.	150 lbs
16" x .160"	100 ft.	134 lbs

- CFM Compliant Material Available.

SCRATCH-SHIELD™

SAFETY ORANGE

PVC STRIP (0° to 150° F)

Width x Thickness	Roll Length	Roll Weight
8" x .072"	150 ft.	60 lbs
12" x .108"	150 ft.	124 lbs

- Bright semi-transparent color used to identify opening perimeters.
- End strips for strip doors.



INSECT CONTROL YELLOW PVC STRIP (0° to 150° F)

Insect Control Yellow

Width x Thickness	Roll Length	Roll Weight
8" x .080"	150 ft.	50 lbs
12" x .120"	150 ft.	113 lbs

- UV Stabilized
- Unique color deters flying insects.
- CFM Compliant Material Available.

Insect Control Yellow Ribbed

Width x Thickness	Roll Length	Roll Weight
8" x .072"	150 ft.	60 lbs
12" x .108"	150 ft.	124 lbs



EXTRUDED CLEAR FILM SHEET (0° to 150° F)

Marine Grade 1S

Super Double Polished Clear, 1S Softness, Mildew Resistant, UV Stabilized

Width x Thickness	Roll Length	Roll Weight
48" x .030"	150'	120 lbs
54" x .030"	114'	100 lbs
60" x .030"	100'	100 lbs
48" x .040"	150'	150 lbs
54" x .040"	84'	100 lbs
60" x .040"	100'	125 lbs
48" x .060"	100'	150 lbs
54" x .060"	60'	100 lbs
60" x .060"	60'	112 lbs

Premium Grade 3S

Super Double Polished Clear, 3S Softness, NFPA 701 Fire Rated, UV Stabilized

Width x Thickness	Roll Length	Roll Weight
48" x .030"	150'	120 lbs
54" x .030"	114'	100 lbs
60" x .030"	100'	100 lbs
48" x .040"	150'	150 lbs
54" x .040"	84'	100 lbs
60" x .040"	100'	125 lbs
48" x .060"	100'	150 lbs
54" x .060"	60'	100 lbs
60" x .060"	60'	112 lbs

Marine Grade 3S


Super Double Polished Clear, 3S Softness, Mildew Resistant, UV Stabilized

Width x Thickness	Roll Length	Roll Weight
48" x .030"	150'	120 lbs
54" x .030"	114'	100 lbs
60" x .030"	100'	100 lbs
48" x .040"	150'	150 lbs
54" x .040"	84'	100 lbs
60" x .040"	100'	125 lbs
48" x .060"	100'	150 lbs
54" x .060"	60'	100 lbs
60" x .060"	60'	112 lbs

Standard Grade 3S

Super Double Polished Clear, 3S Softness, NFPA 701 Fire Rated, UV Stabilized

Width x Thickness	Roll Length	Roll Weight
48" x .030"	150'	120 lbs
54" x .030"	114'	100 lbs
60" x .030"	100'	100 lbs
48" x .040"	150'	150 lbs
54" x .040"	84'	100 lbs
60" x .040"	100'	125 lbs
48" x .060"	100'	150 lbs
54" x .060"	60'	100 lbs
60" x .060"	60'	112 lbs

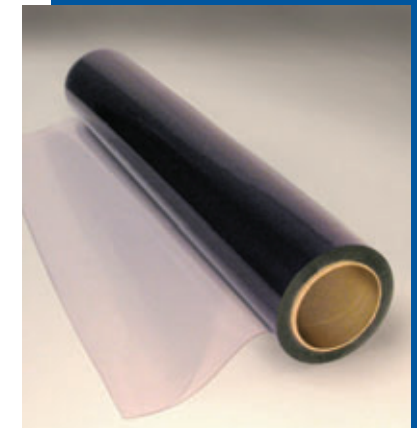

Note: All Strip and Sheet Rolls Ship on 6" Diameter Cores.



STANDARD CLEAR PVC PANEL

(0° to 150° F)

Width x Thickness	Roll Length	Roll Weight	Width x Thickness	Roll Length	Roll Weight
36" x 9/32"	60 ft.	315 lbs	48" x 9/32"	66 ft.	420 lbs
36" x 3/8"	60 ft.	450 lbs	48" x 3/8"	66 ft.	600 lbs
36" x 1/2"	60 ft.	540 lbs	48" x 1/2"	66 ft.	720 lbs
40" x 3/8"	60 ft.	500 lbs	60" x 9/32"	66 ft.	525 lbs
40" x 1/2"	60 ft.	600 lbs	60" x 3/8"	66 ft.	750 lbs
45" x 3/8"	60 ft.	565 lbs	60" x 1/2"	66 ft.	900 lbs



USDA LOW TEMPERATURE CLEAR PVC SHEET

(- 20° to 140° F)

Width x Thickness	Roll Length	Roll Weight	Width x Thickness	Roll Length	Roll Weight
36" x 9/32"	60 ft.	315 lbs	48" x 9/32"	66 ft.	420 lbs
36" x 3/8"	60 ft.	450 lbs	48" x 3/8"	66 ft.	600 lbs
36" x 1/2"	60 ft.	540 lbs	48" x 1/2"	66 ft.	720 lbs
40" x 3/8"	60 ft.	500 lbs	60" x 9/32"	66 ft.	525 lbs
40" x 1/2"	60 ft.	600 lbs	60" x 3/8"	66 ft.	750 lbs
45" x 3/8"	60 ft.	565 lbs	60" x 1/2"	66 ft.	900 lbs



USDA LOW TEMPERATURE OPAQUE PVC SHEET*

(- 20° to 140° F)

Color	Width x Thickness	Roll Length	Roll Weight	Color	Width x Thickness	Roll Length	Roll Weight
White	24" x .080"	120 ft.	60 lbs	White	36" x .080"	120 ft.	180 lbs
Orange	24" x .080"	120 ft.	60 lbs	Orange	36" x .080"	120 ft.	180 lbs
Dark Gray	24" x .080"	120 ft.	60 lbs	Dark Gray	36" x .080"	120 ft.	180 lbs
Royal Blue	24" x .080"	120 ft.	60 lbs	Royal Blue	36" x .080"	120 ft.	180 lbs
Black	24" x .080"	120 ft.	60 lbs	Black	36" x .080"	120 ft.	180 lbs
White	24" x .120"	60 ft.	90 lbs	White	36" x .120"	60 ft.	135 lbs
Orange	24" x .120"	60 ft.	90 lbs	Orange	36" x .120"	60 ft.	135 lbs
Dark Gray	24" x .120"	60 ft.	90 lbs	Dark Gray	36" x .120"	60 ft.	135 lbs
Royal Blue	24" x .120"	60 ft.	90 lbs	Royal Blue	36" x .120"	60 ft.	135 lbs
Black	24" x .120"	60 ft.	90 lbs	Black	36" x .120"	60 ft.	135 lbs

* Low Temp Opaque PVC is special order. Ckeck with your TMI Sale Representative on availability

PEBBLE GRAIN OPAQUE PVC PANEL - SHEET (0° to 150° F)



Color	Width x Thickness	Roll Length	Roll Weight	Color	Width x Thickness	Roll Length	Roll Weight
Beige	38" x .120"	75 ft.	180 lbs	Beige	48" x .120"	75 ft.	225 lbs
Gray	38" x .120"	75 ft.	180 lbs	Gray	48" x .120"	75 ft.	225 lbs
Dark Gray	38" x .120"	75 ft.	180 lbs	Dark Gray	48" x .120"	75 ft.	225 lbs
Blue	38" x .120"	75 ft.	180 lbs	Blue	48" x .120"	75 ft.	225 lbs
Black	38" x .120"	75 ft.	180 lbs	Black	48" x .120"	75 ft.	225 lbs
Green	38" x .120"	75 ft.	180 lbs	Green	48" x .120"	75 ft.	225 lbs
Brown	38" x .120"	75 ft.	180 lbs	Brown	48" x .120"	75 ft.	225 lbs
Black	38" x .120"	75 ft.	180 lbs	Black	48" x .120"	75 ft.	225 lbs
Red	38" x .120"	75 ft.	180 lbs	Red	48" x .120"	75 ft.	225 lbs

Note: PVC Panels Ship on 16" Diameter Cores.
Pebble Grain Rolls Ship on 8" Diameter Cores.

TANK LINING PVC PRODUCTS

TMI, LLC offers flexible PVC products for specialty applications, such as drop-in tank and containment liners. Our tank lining PVC was developed to resist chemicals like sulfuric and nitric acids.

High Temperature PVC - specialty plasticized vinyl with very high heat and chemical resistance (0° to 200° F).

Oil Resistant PVC - polymeric plasticized vinyl with excellent resistance to hydrocarbons and fuel oils (0° to 150° F).

Potable Water PVC - Certified to NSF Standard 61 - approved for use with potable water (0° to 150° F).

Fish Grade PVC - biocide free, fish-grade PVC used to line ponds and tanks (0° to 150° F).

Most tank liner PVC projects are handled on a case-by-case basis, depending on chemical resistance and temperature requirements. Contact TMI for more information on available tank lining products.



RIGID PVC PRODUCTS

TMI, LLC specializes in the manufacturing and distribution of extruded PVC sheets, including a full line of rigid PVC. Extruded rigid PVC sheet can be produced in a large range of colors and formulations. White and black in standard grade are stock compound colors. TMI also specializes in custom production runs.

TMI's rigid PVC sheets have an exceptionally smooth surface to allow for perfect printing. There is no need for decorative overcoats, saving time and money. Quick order turn around, low minimums (5000 lbs.), high quality and knowledgeable technical staff are all marks of TMI, LLC.

Thickness: 0.040" (1.0mm) up to 0.125" (3mm)

Width: up to 50" (1270mm)

Length: 24" (600mm) up to 96" (2.43m)

Our line of PVC sheets includes products for the following industries:

- Signs and Advertising
- Vacuum/Thermo Forming
- Chemical
- Industrial Door
- Environmental
- Building/Construction



MATTING

Our PVC and TPV products are used in a range of flooring and matting applications. PVC offers great durability and price performance. TPV's such as Vyram™ and Santoprene™ offer exceptional durability and wear resistance.


For physical property data sheets and material safety data sheets (MSDS), please contact TMI, LLC at 1-800-888-9750, or visit our website at www.tmi-pvc.com



1-800-888-9750



CONVERSION & FABRICATING SERVICES

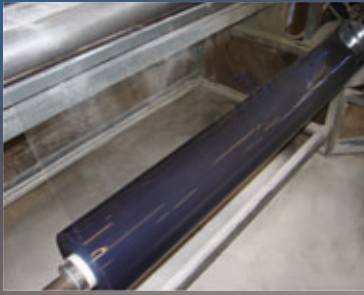

- Slitting & Sheeting
- Interleaving, Dusting & Static Reduction
- Die & Flash Cutting
- RF Heat Sealing
- Normalizing & Welding
- Automatic & Manual Cutting
- Put Up Changes
- Partial Rolls
- Panel Cutting
- Custom Sewing



The largest and most diversified line of flexible PVC products in the industry

Unmatched quality products and services



Managing Environments™

TMI, LLC • 5350 Campbells Run Road • Pittsburgh, PA 15205-9738

800-888-9750

Tel: 412-787-9750 • Fax: 412-787-3665

Web: www.tmi-pvc.com • E-Mail: customer-service@tmi-pvc.com

Copyright © 2011
Catalog Number SV-SS-01-11