

13 1/2" Deep Welded Bookcases

Reinforced for Durability

Extra strength is added in the welding process, providing years of heavy use.

Maximum Rigidity

Shelves have multiple bends at front and rear for additional strength.

Smooth, Clean Lines

Exposed bolts are completely eliminated for a clean professional appearance. Unit tops have no overhang, so side-to-side units will fit flush together.

Integrated Shelf Support Tabs

Built-in shelf support tabs mean no clips to lose.

Shelf Capacity

Durable shelves are designed tough. Each shelf is capable of supporting 120 lbs.

Easy Adjustability

Each shelf adjusts vertically in 2⁵/₆₄" to accommodate materials of any size. Shelves can also be adjusted on 12¹/₂" centers which are clearly identified... perfect for binders.

Double Bottom

Provides extra strength and allows for easy retrieval of materials.



Above unit is shown in our Champagne Putty finish.



6-opening
78" HIGH



5-opening
66" HIGH



4-opening
52" HIGH



3-opening
40" HIGH




2-opening
28" HIGH

Bookcases shown in Sand finish.

13 1/2" Welded Bookcases

You're really going to appreciate the cool, contemporary look of Tennsco's Welded Bookcases. Their smooth front case design offers a style that effortlessly blends into any office decor.

Both highly functional and extremely efficient, Welded Bookcases are available in 2, 3, 4, 5 and 6 opening models. Units are 34 1/2" wide and 13 1/2" deep, providing a stable footing yet allowing for convenient placement in hallways or offices.

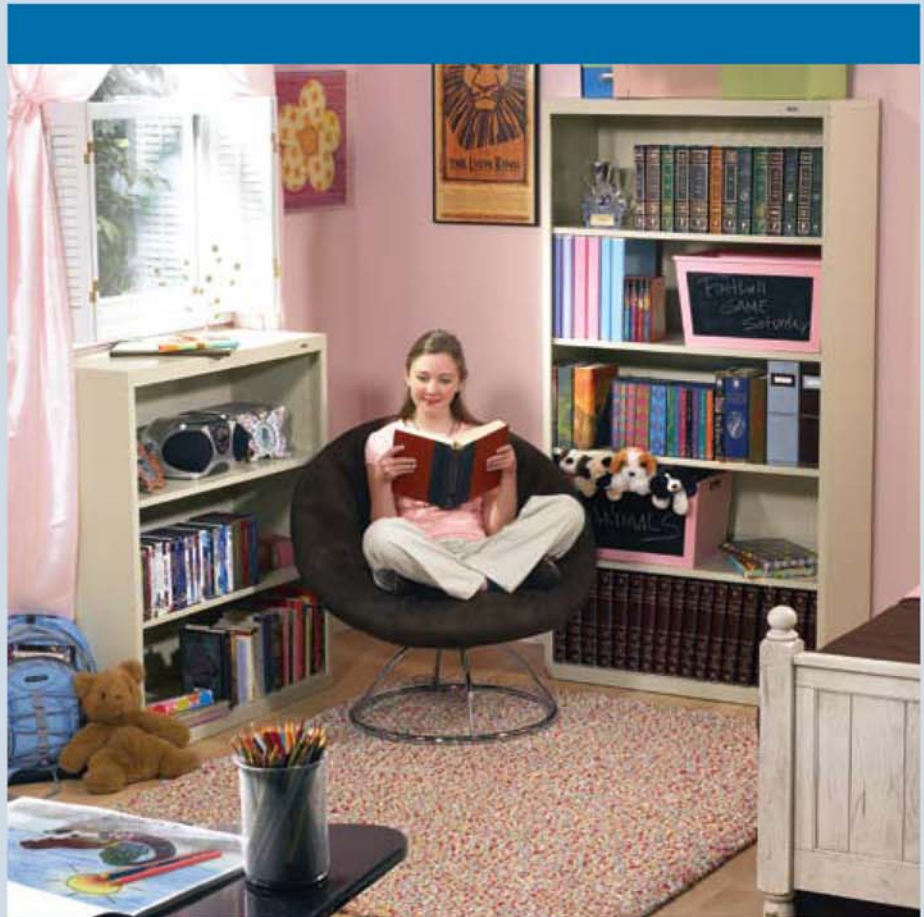

Extra Strength



All cabinet joints are welded for maximum strength and rigidity.

Double Bottom



Double bottom construction design makes retrieving materials easy while providing overall strength to the unit.

Easy Adjustability



Shelves adjust vertically without tools in 2 5/64" increments. Optional adjustable book stop supports materials when shelves are partially filled.

tennsco

SYSTEMS FOR SUCCESS