




**FIRE RATED UNINSULATED ACCESS DOOR**

FOR WALLS ONLY

16M215 - 16M216 - 16M217 - 16M218 - 16M219

INSTALLATION: WALLS ONLY

[ 2 HOUR WALL APPLICATION ]

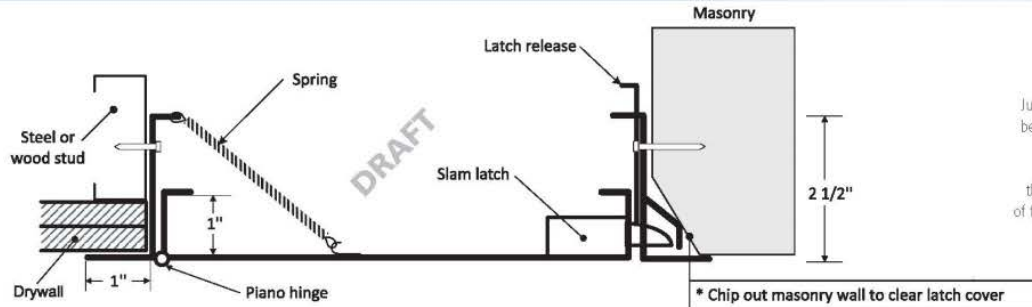


Authorities Having Jurisdiction (AHJ) should be consulted in all cases as to the particular requirements covering the installation and use of fire rated access doors.

DIMENSIONS AND APPEARANCE

PRODUCT CODE	DOOR SIZE W x H inches (MM)	NUMBER OF LOCKS	WEIGHT LBS	WEIGHT KG
16M215	8 x 8 (203 x 203)	1	5	2.3
16M216	12 x 12 (304 x 304)	1	8	3.6
16M217	16 x 16 (406 x 406)	1	12	5.5
16M218	18 x 18 (457 x 457)	1	14	6.4
16M219	24 x 24 (609 x 609)	1	22	10

Rough wall opening is door size + 1/4" or + 6mm

LEED ready: This product contributes to LEED® credits.

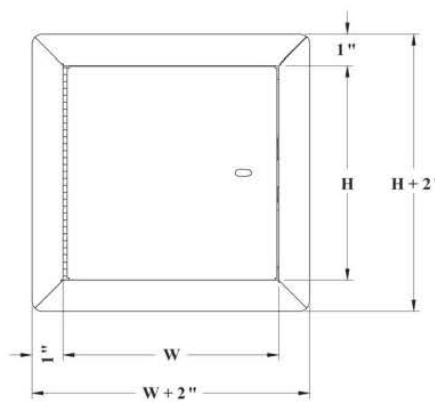

DESCRIPTION AND MATERIAL SPECIFICATION

**FIRE RATING: For vertical wall assemblies only:**

CERTIFIED TO STANDARDS: UBC 7-2 (1997), UL 10B (1997), UL 10B (2009), NFPA 252 (2003), NFPA 252 (2008), NFPA 252 (2012), CAN/ULC S104 (R1985), CAN/ULC S104 (2010).

RATING ACHIEVED: 1-1/2 hours, neutral/negative pressure.

MAXIMUM SIZE: 36" wide x 36" high (914 mm x 914 mm).

Maximum area of 1296 in<sup>2</sup>.

Tolerance on height and width limitation is ± 3" (76 mm)

as long as the area does not exceed 1296 in<sup>2</sup>.

TEMPERATURE RISE: No rating achieved.

**Material:** 16 gauge cold rolled steel

**Hinge:** continuous piano hinge

**Lock / latch:** self latching tool-key operated latch and/or ring operated latch, both included

**Inside panel release:** standard on all doors over 12" x 12"

**Automatic panel closer:** standard on all doors

**Finish:** high quality white powder coat primer

**Packaging:** individually wrapped, 1 per box



**FOR CUSTOM SIZES AND DIFFERENT LOCKING OPTIONS,  
PLEASE CALL YOUR LOCAL GRAINGER BRANCH.**