




**RECESSED ACCESS DOOR**

WITH DRYWALL FLANGE  
16M220 - 16M221 - 16M222

INSTALLATION

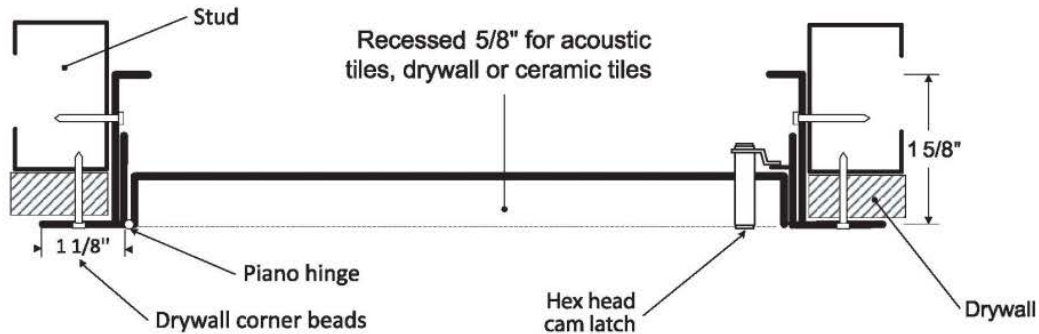


DIMENSIONS AND APPEARANCE

LEED ready: This product contributes to LEED® credits.

PRODUCT CODE	DOOR SIZE W x H inches (MM)	NUMBER OF LOCKS	WEIGHT LBS KG	
16M220	8 x 8 (203 x 203)	1	3	1.4
16M221	12 x 12 (304 x 304)	1	5	2.3
16M222	24 x 24 (609 x 609)	1	16	7.3

Rough wall opening is door size + 1/4" or + 6mm

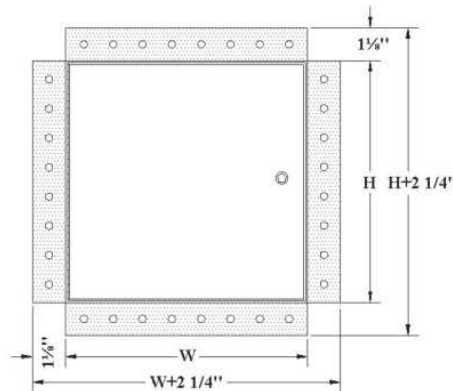

DESCRIPTION AND MATERIAL SPECIFICATION

<b>Material:</b>	16 gauge cold rolled steel	<b>Packaging:</b>	individually wrapped, 1 per box
<b>Hinge:</b>	continuous piano hinge	<b>Recess:</b>	5/8" standard
<b>Lock / latch:</b>	Allen hex head cam latch	<b>GYP:</b>	drywall corner beads flange
<b>Finish:</b>	high quality white powder coat primer		



**FOR CUSTOM SIZES AND DIFFERENT LOCKING OPTIONS,  
PLEASE CALL YOUR LOCAL GRAINGER BRANCH.**