

VAN WALK RAMPS

Magline Has Been Making Quality Aluminum Ramps For Over 40 Years.


- Twin-tooth deck for better traction when traveling in either direction
- Strong, lightweight interlocking aluminum construction makes ramps easily portable and convenient
- All apron models complete with 8" apron; 3-1/4" position stop; safety chains
- All hook models complete with two heavy duty safety hooks
- 4-1/4" Side rail height
- 3-1/4" Curb height



Apron Model

APRON MODEL SPECIFICATIONS											
NOMINAL LENGTHS	MAX HEIGHT RANGE	ACTUAL LENGTH	RATED CAPACITY (LBS)	2,900 SERIES				3,900 SERIES			
				P/N	OVERALL WIDTH	USABLE WIDTH	WEIGHT (LBS)	P/N	OVERALL WIDTH	USABLE WIDTH	WEIGHT (LBS)
3'	9"	36"	3,000	VR29032	28-3/4"	26-1/4"	36	VR39032	39-1/4"	37"	43
4'	12"	45"	3,000	VR29042	28-3/4"	26-1/4"	41	VR39042	39-1/4"	37"	53
5'	18"	63"	3,000	VR29052	28-3/4"	26-1/4"	54	VR39052	39-1/4"	37"	67
6'	21"	72"	2,800	VR29062	28-3/4"	26-1/4"	57	VR39062	39-1/4"	37"	76
7'	27"	90"	2,800	VR29072	28-3/4"	26-1/4"	72	VR39072	39-1/4"	37"	90
8'	31"	99"	2,500	VR29082	28-3/4"	26-1/4"	78	VR39082	39-1/4"	37"	98
9'	34"	108"	2,500	VR29092	28-3/4"	26-1/4"	86	VR39092	39-1/4"	37"	108
10'	37"	117"	2,200	VR29102	28-3/4"	26-1/4"	93	VR39102	39-1/4"	37"	114
12'	46"	144"	1,900	VR29122	28-3/4"	26-1/4"	110	VR39122	39-1/4"	37"	139
14'	52"	162"	1,600	VR29142	28-3/4"	26-1/4"	123	VR39142	39-1/4"	37"	151
16'	61"	189"	1,000	VR29162	28-3/4"	26-1/4"	147	VR39162	39-1/4"	37"	176

Hook Model

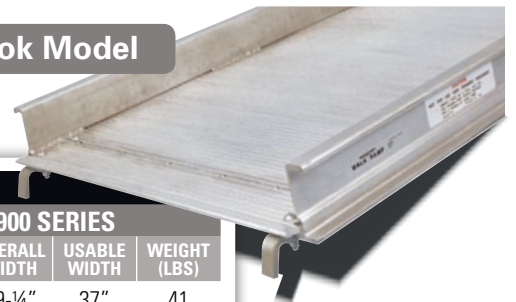

HOOK MODEL SPECIFICATIONS											
NOMINAL LENGTHS	MAX HEIGHT RANGE	ACTUAL LENGTH	RATED CAPACITY (LBS)	2,900 SERIES				3,900 SERIES			
				P/N	OVERALL WIDTH	USABLE WIDTH	WEIGHT (LBS)	P/N	OVERALL WIDTH	USABLE WIDTH	WEIGHT (LBS)
3'	13"	39"	3,000	VR29031	28-3/4"	26-1/4"	33	VR39031	39-1/4"	37"	41
4'	16"	48"	3,000	VR29041	28-3/4"	26-1/4"	40	VR39041	39-1/4"	37"	49
5'	22"	66"	3,000	VR29051	28-3/4"	26-1/4"	50	VR39051	39-1/4"	37"	65
6'	25"	75"	2,800	VR29061	28-3/4"	26-1/4"	56	VR39061	39-1/4"	37"	70
7'	32"	93"	2,800	VR29071	28-3/4"	26-1/4"	72	VR39071	39-1/4"	37"	90
8'	35"	102"	2,500	VR29081	28-3/4"	26-1/4"	75	VR39081	39-1/4"	37"	93
9'	38"	111"	2,500	VR29091	28-3/4"	26-1/4"	83	VR39091	39-1/4"	37"	106
10'	41"	120"	2,200	VR29101	28-3/4"	26-1/4"	89	VR39101	39-1/4"	37"	109
12'	50"	147"	1,900	VR29121	28-3/4"	26-1/4"	107	VR39121	39-1/4"	37"	133
14'	56"	165"	1,600	VR29141	28-3/4"	26-1/4"	119	VR39141	39-1/4"	37"	148
16'	66"	192"	1,000	VR29161	28-3/4"	26-1/4"	140	VR39161	39-1/4"	37"	172

Note: Walk ramps not made for powered equipment or pallet jack use. Recommended for use with hand trucks only.