



U.S. Manufacturer of Signs and Crowd Control Systems Since 1964

Conventional Post and Rope

Decorative post and ropes for that classic look and feel.



- ▶ Durable tie-rod construction for a premium quality post
- ▶ Tightly woven, dense cotton core ropes create a graceful swag
- ▶ Choose from five rope styles in dozens of options, and hundreds of post finishes
- ▶ Ropes can be Dye-Sub printed for additional branding and advertising opportunities
- ▶ Multiple mounting options to suit your environment
- ▶ A true American classic, made from an American manufacturer

Post Options

Urn Top Conventional Stanchions- ST400 Series

	ST400C	ST400D	ST400S
Height	37"	39"	37"
Base Dia.	12"	11.5"	14"
Weight	32 lbs.	32 lbs.	25 lbs.
Stock Finishes	BA, PBA, PA, PC, SC	BA, PBA, PA, PC, SC	BA, PBA, PA, PC, SC, SS
Specialty Finishes	Class 1,2,3	Class 1,2,3	Class 1,2,3

Ball Top Conventional Stanchions - ST500 Series

	ST500C	ST500D	ST500S
Height	40"	42"	40"
Base Dia.	12"	11.5"	14"
Weight	32 lbs.	32 lbs.	25 lbs.
Stock Finishes	BA, PBA, PA, PC, SC	BA, PBA, PA, PC, SC	BA, PBA, PA, PC, SC, SS
Specialty Finishes	Class 1,2,3	Class 1,2,3	Class 1,2,3

Flat Top Conventional Stanchions- ST600 Series

	ST600C	ST600D	ST600S	ST601U
Height	34"	36"	34"	34"
Base Dia.	12"	11.5"	14"	14"
Weight	30 lbs.	30 lbs.	23 lbs.	23 lbs.
Stock Finishes	BA, PBA, PA, PC, SC	BA, PBA, PA, PC, SC	BA, PBA, PA, PC, SC, SS	YA
Specialty Finishes	Class 1,2,3	Class 1,2,3	Class 1,2,3	N/A

Loop Post

See our Loop Post flyer for a simple outdoor post. This stainless steel post is ideal for large outdoor queue lines such as at amusement parks. Recommended for use with chains or weatherproof ropes.

- ▶ 2 or 4 Loops
- ▶ Single or Dual Line
- ▶ Five Base Styles

Other Mounting Options For Conventional Posts

	Fixed (Permanent Post)	Removable (Permanent Socket, Removable Post)	Mini Socket (Permanent Socket, Removable Post)	Magnetic* (Permanent Plate, Removable Post)	Slim Socket (Permanent Socket, Removable Post)
Height	36" - 42"	36" - 42"	36" - 40.25"	38.5" - 42.75"	This no-flange socket is available with the Loop Post only. Minimum quantities may apply. Loop Post is also available with a Sloped Base. See Loop Post flyer for more details.
Base Dia.	5"	2"	2"	6.25"	
Weight	10 - 12 lbs.	11 - 13 lbs.	10 - 12 lbs.	13 - 15 lbs.	
Stock Finishes	PC, SC, SS, SB	PC, SC, SS, SB	BA, PA, PBA, PC, SC, SS	BA, PA, PBA, PC, SC, SS	
Specialty Finishes	Class 1,2,3	Class 1,2,3	Class 1,2,3	Class 1 & 2	

*Not available on Loop Post

Rope Options & Accessories

Each rope is crafted per order and hand-wrapped in the highest quality materials of your choice. The plush coverings are wrapped and stitched around the tightly woven cotton core to provide an elegant swag between posts. Accent your ropes with durable snap or hook ends in your choice of finish to complete the classic look of your post and rope set.

Signage: easy to add. Top will be drilled and tapped for no charge when specified (excludes ball top).

Forged ring: Thick and strong, rounded for safety. Accepts 1.5" diameter ropes or chains with hook or snap ends.

Ultra high quality ropes: in your choice of cover or material, snap ends style and finish.

Durable tie-rod construction: full length center rod keeps tension between the post cap and base to ensure they will not loosen and fall apart over time.

Heavy construction: components will last for years and are highly resistant to denting.

Rubber floor protectors: standard with all bases.

Velour: Our classic, elegant velour is the standard at red carpet events.



Naugahyde: Durable, easy to maintain naugahyde is suitable for mild outdoor use and wipes clean when necessary. Ideal for sidewalks and outdoor food areas.



Braided Polypropylene: Suitable for outdoor use and other utilitarian purposes. This weatherproof "twisted plastic" rope is available in five colors.



*Braided Polypropylene rope is 1-1/2" diameter, without a cotton core

Leather: 100% recycled leather is available in four standard color options, with dozens of other colors and textures available upon request.



Microfiber: Feel luxury on your fingertips with our new microfiber rope option. It's soft, strong, and easy to clean.



Dye-Sub Microfiber: Customize your ropes with hundreds of color options, as well as patterns, images and logos.




Chains: A durable and economical barrier between posts. Recommended for use with Stainless Steel Loop Posts.



Wall Plates and Magnetic Breakaways

Magnetic breakaways allow for an easy exit in an emergency situation, as required by some fire codes

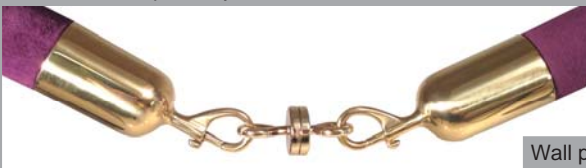

Hook Ends have no closing mechanism



Wall plates accept two ropes and eliminate the need for an additional post



Finishes & Rope Options for Conventional Posts



Stock Finishes <small>(Note 1)</small>							
Finish							
	Black Aluminum	Yellow Aluminum	Polished Brass Aluminum	Polished Aluminum	Polished Chrome	Satin Chrome	Satin Stainless Steel
Order Code	BA	YA	PBA	PA	PC	SC	SS
Price	\$	\$	\$\$	\$\$	\$\$\$	\$\$\$	\$\$\$\$
Luster	N/A	N/A	***	***	****	****	****
Durability	***	***	***	***	****	****	****
Post Top Material	Brass	Brass	Brass	Brass	Brass	Brass	Brass
Post Material	Alum.	Alum.	Alum.	Alum.	Steel	Steel	304 Stainless Steel <small>(Note 2)</small>
Base Cover Material	Black ABS (Sloped) Steel (Others)	Black ABS	Brass (Dome) Steel (Others)	Steel	Steel	Steel	304 Stainless Steel <small>(Note 2)</small>
Weather Resistant	(Sloped)						

(1) Stock finishes are generally available for immediate delivery.
(2) Grade 304 Stainless Steel is a high strength, rust resistant alloy. BEWARE: Many low cost products use Grade 201 Stainless Steel is highly susceptible to rusting.

Specialty Finishes <small>(Note 3)</small>												
Finish	Class 1 - Powder Coat over Steel Posts											
	Smooth Black	Wrinkle Black	Charcoal	Grey	White	Red	Green	Blue	Brown	Beige	Silver Vein	Gold Vein
Order Code	SB	WB	CH	GR	WH	RD	GN	BL	BN	BG	SV	GV
Price	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$	\$\$\$
Luster	N/A	N/A	N/A	N/A	N/A	N/A	N/A	N/A	N/A	N/A	N/A	N/A
Durability	****	****	****	****	****	****	****	****	****	****	****	****
Post Top Material	Brass	Brass	Brass	Brass	Brass	Brass	Brass	Brass	Brass	Brass	Brass	Brass
Post Material	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel
Base Cover Material	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel	Steel

Finish	Class 2 - Brass Plating over Steel			Class 3 - Solid Brass <small>(Notes 4-5)</small>		
	Polished Brass Plated	Satin Brass Plated	Statuary Bronze Plated	Polished Brass w/ Clear Coat	Satin Brass w/ Clear Coat	Statuary Bronze w/ Clear Coat
Order Code	PB2	SB2	SBZ2	PB3	SB3	SBZ3
Price	\$\$\$\$	\$\$\$\$	\$\$\$\$	\$\$\$\$\$	\$\$\$\$\$	\$\$\$\$\$
Luster	*****	*****	*****	*****	*****	*****
Durability	****	****	****	*****	*****	*****
Post Top Material	Brass	Brass	Brass	Brass	Brass	Brass
Post Material	Steel	Steel	Steel	Brass	Brass	Brass
Base Cover Material	Brass (Dome) Steel (Others)	Steel	Steel	Brass	Brass	Brass
Weather Resistant						

(3) Specialty finishes require a minimum order of 5 pieces and a 2 week lead time. Call if quicker delivery is needed.
(4) Solid brass products include a protective clear coat to prevent tarnishing. Also available without clear coat upon request.
(5) Class 3 finishes require special clear coat for outdoor use. Additional charges apply.

Rope Options			
Velour (841) BK - Black PG - Pearl Grey (PMS Cool Gray 9C) BG - Beige (PMS 4725) BN - Brown (PMS 497) MN - Maroon (PMS 195) RD - Red (PMS 7427) AG - Antique Gold (PMS 117)		Braided Polypropylene (843) BK - Black YW - Yellow (PMS 108) RD - Coral Red* (PMS 187) WH - White NH - Natural Hemp <p><small>*Coral Red may be susceptible to fading. Due to printing limitations, colors shown may not represent actual product colors. Please call for samples if required.</small></p>	
HG - Hunter Green (PMS 350) BL - Blue (PMS 282) PL - Purple (PMS 518) PK - Light Pink (PMS 197)		Recycled Leather (844) BN - Brown (PMS 497) WH - White LB - Light Beige (PMS 7530) PT - Pewter (PMS Cool Gray 10)	
Naugh Hyde (842) BK - Black BL - Blue (PMS 296) RD - Red (PMS 202)		Microfiber (845) ML - Merlot (PMS 209) WH - White LG - Light Green (PMS 5763) OB - Ocean Blue (PMS 5415) BK - Black Dye-sub Microfiber 	
Chains 1/8" Zinc Plated - 851ZP 3/16" Pol. Stainless Steel - 852PS			