


D1216-3 MODEL

★★
225 lbs.
LOAD CAPACITY
Type II
Duty Rating



Reduces to 6'

- Versatile- Use indoors or outdoors
- Same usable length as a standard 16' extension ladder
- Easy to maneuver around corners and through doors

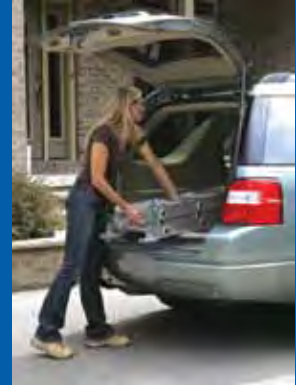

Fits in most cars for easy transport



Reduces to 6' for easy storage



Convenient carrying handle





D1216-3 Model

- Reduces to 6' with the same usable length as a standard 16' extension ladder
- Maneuvers around corners and doors for convenient indoor use
- Compact design fits in most cars for hassle-free transport
- Convenient carrying handle attached for easy, single-handed moving
- More overlapping rung locations for improved working comfort

Compact Extension Ladder Model D1216-3

**REDUCES
TO 6'**



★★
225 LOAD CAPACITY
lbs.
Combined weight of User and Materials

SPECIFICATIONS

| Model No. | Total Length of Sections | Ladder Size | Max. Working Length | Highest Standing Height | Approx. Cu. Ft. Per Unit | Approx. Shipping Wt. (Lbs.) |
|----------------|--------------------------|-------------|---------------------|-------------------------|--------------------------|-----------------------------|
| D1216-3 | 18' | 16' | 13' | 9'3" | 5.92 | 26.5 |

24' version, model D1224-3, available for larger jobs

STORAGE SIZE COMPARISON (Standard 2-piece vs. New 3-piece)

| Ladder Size | Standard Extension Ladder | D1200-3 Series |
|-------------|---------------------------|----------------|
| 16' | 8' | 6' |
| 24' | 12' | 9' |