


1. MATERIAL: Steel
2. ABEC TOLERANCE: 1
3. TYPE: Double Shielded
4. ITEM: Radial Ball Bearing
5. LUBRICATION: SRI#2 Grease
6. TEMP. RANGE: -20°F to 250°F
7. STATIC LOAD CAPACITY: 540Lb.
8. DYNAMIC LOAD CAPACITY: 1,150Lb.
9. SHIELD MATERIAL: Rust-Resistant Metal

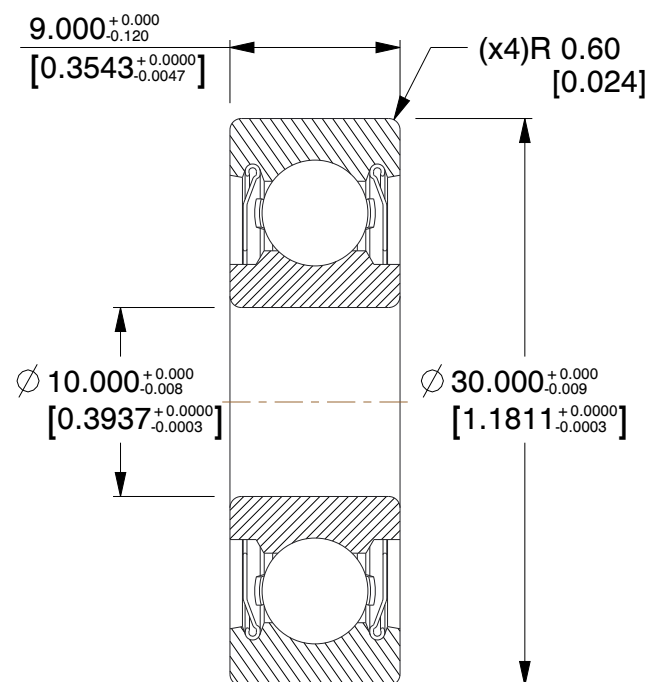

COMPONENT		Radial Ball Bearing	
e	<div>1L013</div> <div>10 x 30 x 9 Radial Bearing, Double Shield, 10mm Bore</div>		UNIT
			MM
			SHEET
			1 of 1