



Ø 0.688
Flange Dia.

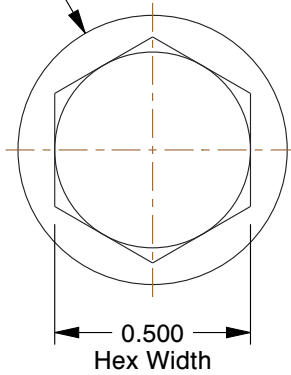

0.313
Hex Height

0.050

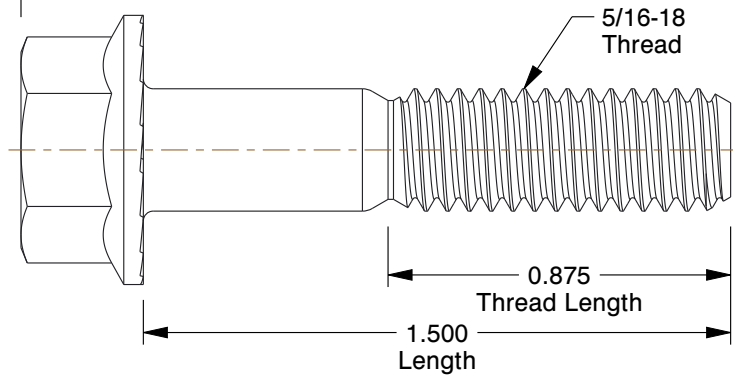

NOTES:

1. HEAD TYPE : Hex Serrated Flange
2. MATERIAL : Steel
3. FINISH : Zinc Plated
4. THREAD STYLE : Partially Threaded
5. SCREW GRADE/CLASS : Grade 5
6. ROCKWELL HARDNESS : C25 to C34
7. SCREW INDUSTRY STANDARDS : ASME B18.2.1
8. TENSILE STRENGTH : 120,000 psi
9. THREAD TYPE : UNC (Coarse)

COMPONENT	Hex Head Cap Screw
------------------	--------------------



100 Grainger Parkway, Lake Forest, Illinois 60045-5201
1-(800) GRAINGER, 1-(800) 472-4643, (847) 535-1000
www.grainger.com

This file and any associated information and specifications are provided for reference and evaluation purposes only, and is subject to change without notice. Grainger makes no representations, warranties or guarantees as to the appropriateness, accuracy, completeness, or suitability for any purpose, of the file, information or specifications. You are solely responsible for the use of the file, information or specifications.

This drawing is the property of GRAINGER. It contains confidential, proprietary information that is GRAINGER property. Do not disclose to or duplicate for others except as authorized by GRAINGER.

SCALE 2.04

2FE20
Hex Cap Screw, Gr 5, 5/16-18x1-1/2, PK50

UNIT	INCH
SHEET	1 of 1